


LED Spotlights

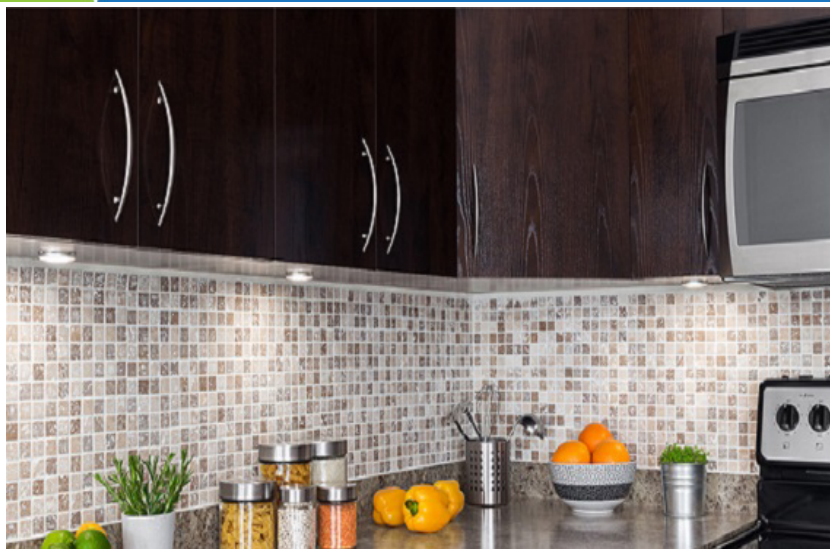

VT-247D

HIGHLIGHTS :

WATTS



6.5

EQ. WATTS



55

LUMINOUS



450

BEAM ANGLE



110

PRODUCT FEATURES

Item No	: VT-247D
SKU Code	: 199
Watts	: 6.5
EQ. Watts	: 55
Base / holder	: GU10
Voltage	: AC:220-240V,50Hz
Lumen(lm)	: 450
Color Temperature	: 4000K
Beam Angle	: 110
PF	: >0.5
LED Chip Type	: SMD-Samsung Chip
CRI	: >80
Energy rating label	: A+
IP Rating Protection Class	: IP20
Body type	: Plastic
Dimmable	: Yes
Life Time	: 30,000 Hours
EAN code	: 3800157631648
Unit size	: ø50x55mm
Packing details	: 200.00