


KEMET, EFX6, Flex Suppressors, Commercial Grade

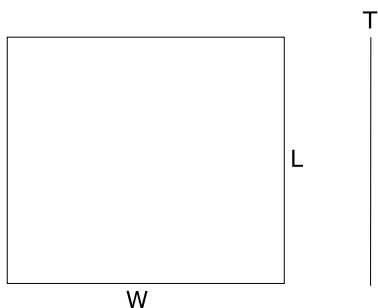

General Information	
<b>Series:</b>	EFX6
<b>Style:</b>	Sheet
<b>Description:</b>	Flex Suppressor High Permeability Type
<b>Features:</b>	High Permeability Type
<b>RoHS:</b>	Yes
<b>Qualifications:</b>	UL94 HB, UL File No. E176124
<b>Environment:</b>	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Dimensions	
<b>Sheet Size</b>	240x240mm
<b>L</b>	240mm NOM
<b>W</b>	240mm NOM
<b>T</b>	0.3mm NOM

Specifications	
<b>Temperature Range:</b>	-40/+105C
<b>Effective Frequency:</b>	10 GHz MAX
<b>Resistance:</b>	1 MOhms MIN
<b>Specific Gravity:</b>	3.8 Atm TYP

Packaging Specifications	
<b>Tape Description:</b>	No Adhesive Tape