


KEMET, FF1, Flex Suppressors, Commercial Grade

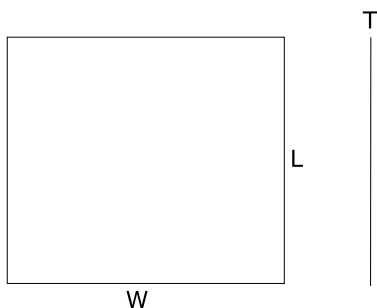

General Information	
Series:	FF1
Style:	Sheet
Description:	Flex Suppressor Flame Retardant Type
Features:	Flame Retardant Type
RoHS:	Yes
Qualifications:	UL94 V-0, UL File No.E176124, AEC-Q200
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free

Dimensions	
Sheet Size	240x240mm
L	240mm NOM
W	240mm NOM
T	0.3mm NOM

Specifications	
Temperature Range:	-40/+105C
Magnetic Permeability:	100 TYP At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.1 Atm TYP
Conductivity:	1.8 W/m K
Tensile Strength:	10.8 MPa MIN

Packaging Specifications	
Tape Description:	No Adhesive Tape