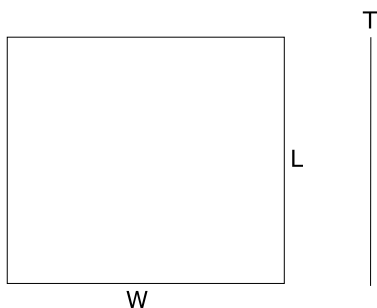


KEMET, EFF4, Flex Suppressors, Commercial Grade

**Dimensions**

Sheet Size	240x240mm
L	240mm NOM
W	240mm NOM
T	0.5mm NOM

Packaging Specifications

Tape Description:	No Adhesive Tape
-------------------	------------------

General Information

Series:	EFF4
Style:	Sheet
Description:	Flex Suppressor Flame Retardant Type
Features:	Flame Retardant Type
RoHS:	Yes
Qualifications:	UL94 V-0, UL File No.E176124, AEC-Q200
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free

Specifications

Temperature Range:	-40/+105C
Magnetic Permeability:	140 TYP At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.7 Atm TYP