

Fluke 289 FlukeView® Forms Combo Kit



Maximize productivity with the combined Fluke 289 and FlukeView® Forms Combo Kit. With built-in data logger and TrendCapture capability, the 289 helps you track down elusive, intermittent problems, monitoring equipment with any of its functions while you do other jobs. Using FlukeView Forms software allows you to overlay your logged data from six meters or six time periods to find cause and effect relationships or for condition monitoring. Turn your data into meaningful graphs and tables for a professional report or analyze individual readings or series of measurements. The 289/FVF combo kit gives you a practical and affordable approach to predictive maintenance.


Fluke-289/FVF Kit includes:

- Fluke-289 True-rms Industrial Logging Multimeter with TrendCapture, LoZ, LoPass filter, and Lo Ohms
- FVF-SC2 FlukeView Forms Software and cable
- TL71 Silicon Test Lead Set
- AC72 Alligator Clips
- 80BK-A Integrated DMM Temperature Probe
- TPAK Magnetic Meter Hanger for hands-free operation
- C280 Soft Case for meter protection and accessory storage

Technical Data

289 functions and features

Multiple on-screen displays	Yes
LoZ	Yes
50 ohm range	Yes
Filter for measurements on motor drives	Yes
True-rms ac bandwidth	100 kHz
DBV/dBm	Yes
DC mV resolution	1 μ V
Megohm range	500 M Ω
Conductance	50.00 nS
Continuity beeper	Yes
Temperature ($^{\circ}$ C and $^{\circ}$ F)	-200 $^{\circ}$ C to 1350 $^{\circ}$ C
Battery/fuse access	Yes/Yes
Elapsed time clock	Yes
Time of day clock	Yes
Min-Max-Avg	Yes
Frequency	Yes
Duty cycle/pulse width	Yes
Info button on board help	Yes
Hold	Yes
Isolated optical interface	Yes
Auto/touch hold	Yes
Reading memory	Yes
Log to PC	Yes
On board logging with TrendCapture	Yes
Logging memory	180 hours

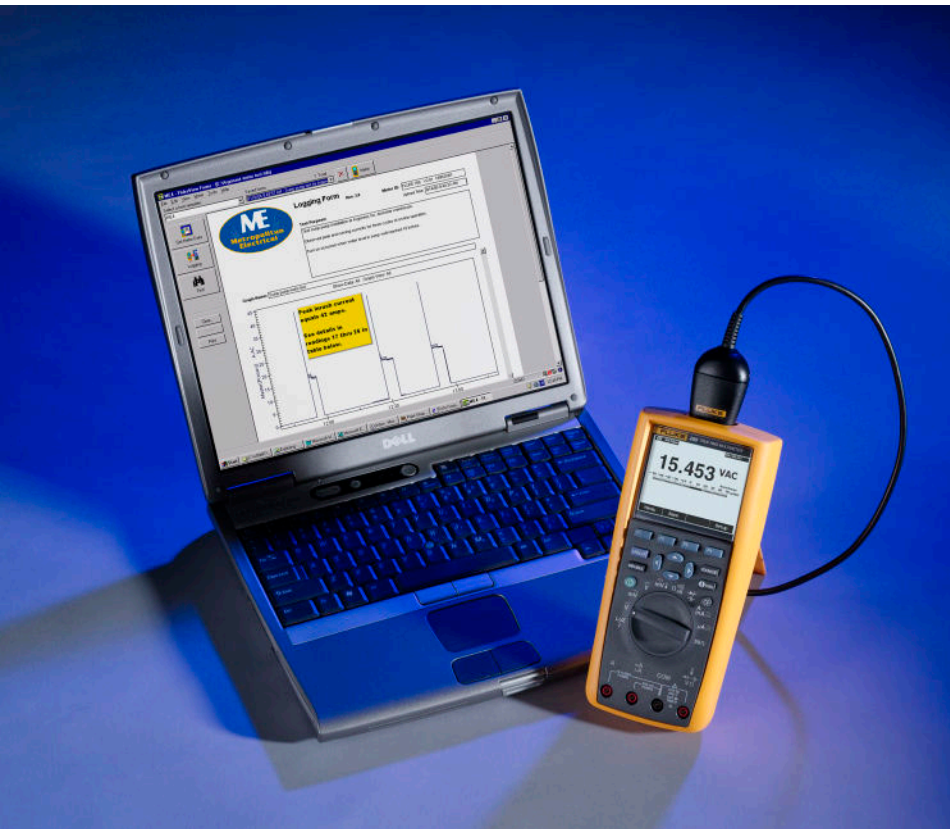

Ordering information

Fluke-289/FVF True-rms Logging Multimeter Combo Kit with TrendCapture

289 specifications

Function	Range and resolution	Basic accuracy
DC volts	50.000 mV, 500.00 mV, 5.0000 V, 50.000 V, 500.00 V, 1000.0V	0.025 %
AC volts		0.4 % (true-rms)
DC current	500.00 µA, 5000.0 µA, 50.000 mA, 400.00 mA, 5.0000 A, 10.000 A	0.15 %
AC current		0.7%(true-rms)
Temperature (excluding probe)	-200.0 °C to 1350.0 °C (-328.0 °F to 2462.0 °F)	1.0 %
Resistance	50.000 Ω (289 only), 500.00 Ω, 5.0000 kΩ, 50.000 kΩ, 500.00 kΩ, 5.0000 MΩ, 50.00 MΩ, 500.0 MΩ	0.05 %
Capacitance	1.000 nF, 10.00 nF 100.0 nF, 1.000 µF, 10.00 µF, 100.0 µF, 1000 µF, 10.00 mF, 100.00 mF	1.0 %
Frequency	99.999 Hz, 999.99 Hz, 9.9999 kHz, 99.999 kHz, 999.99 kHz	0.005 % + 1

Fluke. Keeping your world up and running.®

Fluke Corporation
PO Box 9090, Everett, WA USA 98206

Fluke Europe B.V.
PO Box 1186, 5602 BD Eindhoven, The Netherlands

For more information call:
In the U.S.A. (800) 443-5853 or Fax (425) 446-5116
In Europe/M-East/Africa +31 (0) 40 2675 200 or Fax +31 (0) 40 2675 222
In Canada (800)-36-FLUKE or Fax (905) 890-6866
From other countries +1 (425) 446-5500 or Fax +1 (425) 446-5116
Web access: <http://www.fluke.com>

©2007 Fluke Corporation. All rights reserved.
Specifications subject to change without notice.
Printed in U.S.A. 7/2007 3062469 D-EN-N Rev A

Fluke Connect™ ir3000 FC Connector

Technical Data

Connect your Fluke test tool with the ir3000 FC Connector and get all the benefits of the Fluke Connect mobile app



If you already have one of the tools below in your tool box or tool belt or are considering purchasing one, add the ir3000 FC Connector so you can communicate with Fluke Connect™ app.

- Fluke Connect ir3000 FC Connector allows you to wirelessly transfer data from your existing Fluke tools to your smart phone
- Fits over the IR port of your existing Fluke tools
- Immediately enables you to graph, save, and share the tool's readings with your team from your smart phone
- Identify and diagnose problems quickly and confidently
- Efficiently and safely capture real-time readings of the primary display from the field
- Share results instantly with your team
- Upgradeable by USB

Supported Fluke tools:

- Digital Multimeter: 187, 189, 287, 289
- Process Tool: 789

Supported smart phones:

- Android™ 4.4 & up
- iPhone® 4s & later

Review the information on both models below to ensure you are selecting the one that supports your existing Fluke tool. Next, download the Fluke Connect mobile app from the Apple or Google app store and get started.



Built with
**FLUKE
CONNECT™**

**See it. Save it. Share it.
All the facts, right in the field.**

Fluke Connect with ShareLive™ video call is the only wireless measurement system that lets you stay in contact with your entire team without leaving the field. The Fluke Connect mobile app is available for Android™ (4.4 and up) and iOS (4s and later) and works with over 20 different Fluke products—the largest system of connected test tools in the world. And more are on the way. Go to the Fluke website to find out more.

Make the best decisions faster than ever before by viewing all temperature, mechanical, electrical and vibration measurements for each equipment asset in one place. Get started saving time and increasing your productivity.

Download the app at:



Smart phone, wireless service and data plan not included with purchase.

General specifications

Model	FLUKE-IR3000FC
Battery type	Two AAA Alkaline batteries, ANSI-24A IEC-LR03
Battery life	6 hours of continuous transmission
RF communications	2.4 GHz ISM Band
RF communication range	Open air, unobstructed: Up to 20 m Obstructed, sheetrock wall: Up to 6.5 m Obstructed, concrete wall or steel electrical enclosure: Up to 3.5 m
Temperature	Operating: -10 °C to 50 °C Storage: -20 °C to 60 °C
Certifications	CSA, FCC, CE, IC
Warranty	Three years
Weight	80 g
Size (HxWxL)	3.2 cm x 7.6 cm x 6.4 cm (1.25 in x 3.0 in x 2.5 in)
Compatibility	Fluke 187, 189, 287, 289, 789

Ordering information

FLUKE-IR3000FC Fluke Connect ir3000 FC Connector

RF connection time (binding time) may take up to 1 minute.

Fluke. *Keeping your world up and running.*®

Fluke Corporation
PO Box 9090, Everett, WA 98206 U.S.A.

Fluke Europe B.V.
PO Box 1186, 5602 BD
Eindhoven, The Netherlands

For more information call:
In the U.S.A. (800) 443-5853 or
Fax (425) 446-5116
In Europe/M-East/Africa +31 (0) 40 2675 200 or
Fax +31 (0) 40 2675 222
In Canada (800)-36-FLUKE or
Fax (905) 890-6866
From other countries +1 (425) 446-5500 or
Fax +1 (425) 446-5116
Web access: <http://www.fluke.com>

Footnote: All trademarks are the property of their respective owners. Smart phone, wireless service and data plan not included with purchase. First 5 GB of storage is free. Compatible with iPhone 4x and up running iOS 7 or higher, iPad (in an iPhone frame on iPad) and Galaxy S4, Nexus 5, HTC One running Android™ 4.4.x or higher. Apple and the Apple logo are trademarks of Apple Inc. registered in the U.S. and other countries. App Store is a service mark of Apple Inc. Google Play is a trademark of Google Inc.

©2014 Fluke Corporation.
Specifications subject to change without notice.
Printed in U.S.A. 9/2014 6002159D_EN

Modification of this document is not permitted without written permission from Fluke Corporation.