



Classic filament LED Lamps

CLA LEDBulb ND 7-60W B22 WW ST64 CL

Featuring a classic heritage design, Classic filament LED Lamps combine the familiar shapes of classic incandescent bulbs with the benefits of the long lasting LED technology. They deliver beautiful, decorative warm-white light while saving around 90% on energy costs compared with traditional light bulbs.

Product data

General Information	
Cap-Base	B22 [B22]
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X
Technical Type	7-60W
Light Technical	
Color Code	827 [CCT of 2700K]
Luminous Flux (Nom)	806 lm
Luminous Flux (Rated) (Nom)	806 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (Rated) (Nom)	115.14 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	50 to 60 Hz
Power (Rated) (Nom)	7 W


Lamp Current (Nom)	60 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.5
Voltage (Nom)	220-240 V
Temperature	
T-Case Maximum (Nom)	45 °C
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Finish	Clear
Approval and Application	
Energy Efficiency Label (EEL)	A++
Energy Consumption kWh/1000 h	7 kWh

Classic filament LED Lamps

Product Data	
Full product code	871869674279200
Order product name	CLA LEDBulb ND 7-60W B22 WW ST64 CL
EAN/UPC - Product	8718696742792
Order code	929001387702
Numerator - Quantity Per Pack	1

Numerator - Packs per outer box	10
Material Nr. (12NC)	929001387702
Net Weight (Piece)	0.048 kg



Dimensional drawing

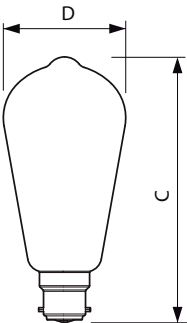


Bulb ST64 230V 7-60W 806lm 2700K B22 ND

Product	D	C
CLA LEDBulb ND 7-60W B22 WW ST64 CL	64 mm	138 mm

Photometric data

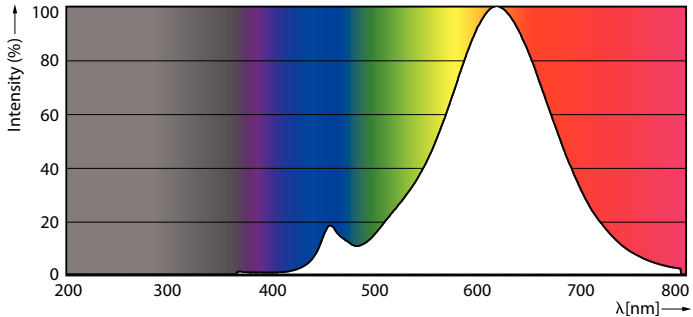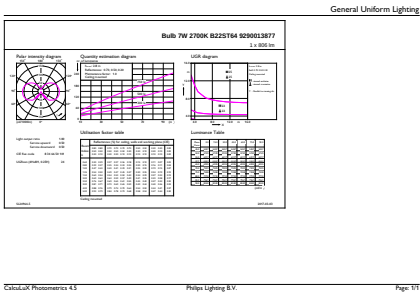


LEDbulb 60W E27 827 CL A60 ND

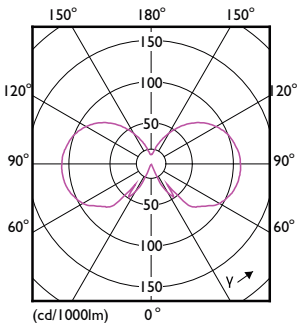


LEDbulb 60W E27 827 CL A60 ND

Classic filament LED Lamps

Lifetime

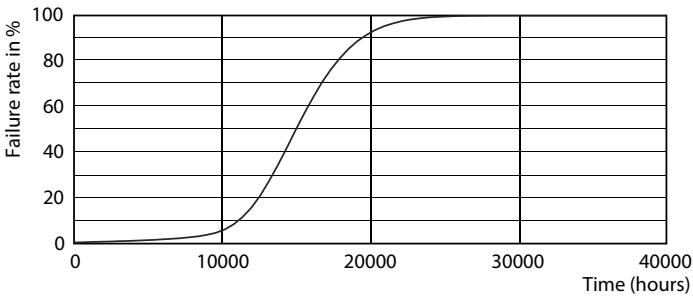

LEDbulb 60W E27 827 CL A60 ND

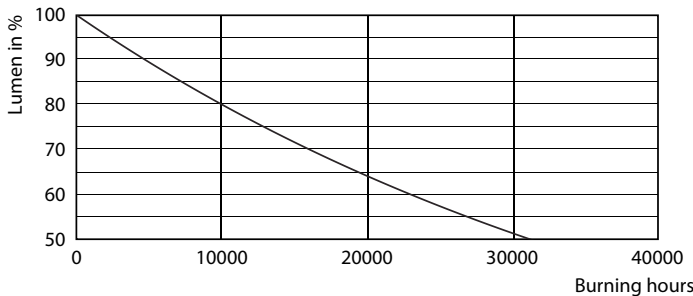

LEDbulb 60W E27 827 CL A60 ND

