



Classic filament LED Lamps

CLA LEDCandle D 5-40W B35 E14 827 CL

Featuring a classic heritage design, Classic filament LED Lamps combine the familiar shapes of classic incandescent bulbs with the benefits of the long lasting LED technology. They deliver beautiful, decorative warm-white light while saving around 90% on energy costs compared with traditional light bulbs.

Product data


General Information			
Cap-Base	E14 [E14]	Lamp Current (Nom)	28 mA
Nominal Lifetime (Nom)	15000 h	Wattage Equivalent	40 W
Switching Cycle	20000X	Starting Time (Nom)	0.5 s
Technical Type	5-40W	Warm Up Time to 60% Light (Nom)	0.5 s
Light Technical		Power Factor (Nom)	0.7
Color Code	827 [CCT of 2700K]	Voltage (Nom)	220-240 V
Luminous Flux (Nom)	470 lm	Temperature	
Luminous Flux (Rated) (Nom)	470 lm	T-Case Maximum (Nom)	60 °C
Color Designation	Warm White (WW)	Controls and Dimming	
Correlated Color Temperature (Nom)	2700 K	Dimmable	Yes
Luminous Efficacy (Rated) (Nom)	94.00 lm/W	Mechanical and Housing	
Color Consistency	<6	Bulb Finish	Clear
Color Rendering Index (Nom)	80	Approval and Application	
LLMF At End Of Nominal Lifetime (Nom)	70 %	Energy Efficiency Label (EEL)	A+
Operating and Electrical		Energy Consumption kWh/1000 h	5 kWh
Input Frequency	50 to 60 Hz		
Power (Rated) (Nom)	5 W		

Classic filament LED Lamps

Product Data	
Full product code	871869670982500
Order product name	CLA LEDCandle D 5-40W B35 E14 827 CL
EAN/UPC - Product	8718696709825
Order code	929001332102
Numerator - Quantity Per Pack	1

Numerator - Packs per outer box	10
Material Nr. (12NC)	929001332102
Net Weight (Piece)	0.014 kg




Dimensional drawing

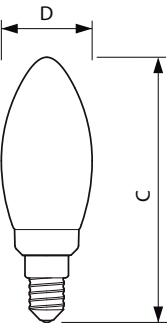

CandleB35 230V4.5-40W470lm 2700K D Clear

Product	D	C
CLA LEDCandle D 5-40W B35 E14 827 CL	35 mm	103 mm


Photometric data

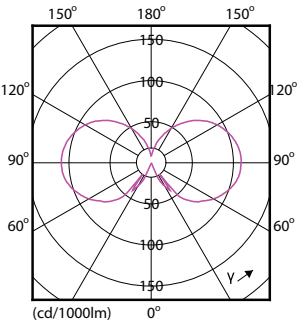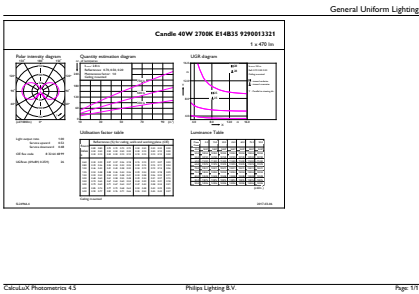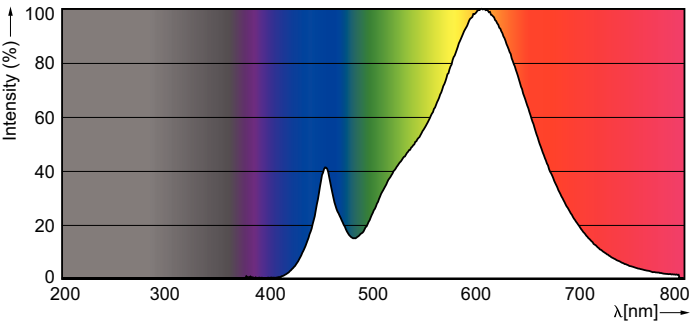


LEDbulb 40W E14 827 CL B35

Classic filament LED Lamps

Lifetime

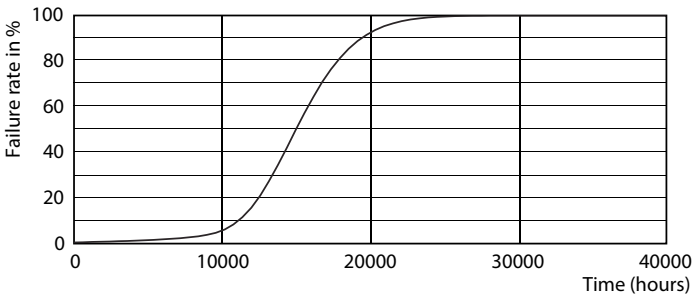

LEDbulb 40W E27 827 CL A60 D

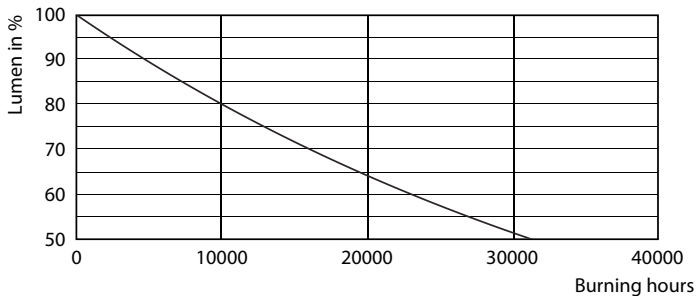

LEDbulb 40W E27 827 CL A60 D

