



Classic filament LED Lamps

CLA LEDCandle ND 4-40W B35 B22 827 CL

Featuring a classic heritage design, Classic filament LED Lamps combine the familiar shapes of classic incandescent bulbs with the benefits of the long lasting LED technology. They deliver beautiful, decorative warm-white light while saving around 90% on energy costs compared with traditional light bulbs.

Product data

General Information	
Cap-Base	B22 [B22]
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X
Technical Type	4-40W
Light Technical	
Color Code	827 [CCT of 2700K]
Luminous Flux (Nom)	470 lm
Luminous Flux (Rated) (Nom)	470 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (Rated) (Nom)	118.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	50 to 60 Hz
Power (Rated) (Nom)	4 W


Lamp Current (Nom)	36 mA
Wattage Equivalent	40 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.4
Voltage (Nom)	220-240 V
Temperature	
T-Case Maximum (Nom)	45 °C
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Finish	Clear
Approval and Application	
Energy Efficiency Label (EEL)	A++
Energy Consumption kWh/1000 h	4 kWh

Classic filament LED Lamps

Product Data	
Full product code	871869676694100
Order product name	CLA LEDCandle ND 4-40W B35 B22 827 CL
EAN/UPC - Product	8718696766941
Order code	929001815802
Numerator - Quantity Per Pack	1

Numerator - Packs per outer box	10
Material Nr. (12NC)	929001815802
Net Weight (Piece)	0.010 kg



Dimensional drawing

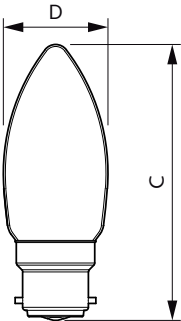


Candle 230V 4-40W 470lm 2700K B22 ND B35

Product	D	C
CLA LEDCandle ND 4-40W B35 B22 827 CL	35 mm	93 mm

Photometric data

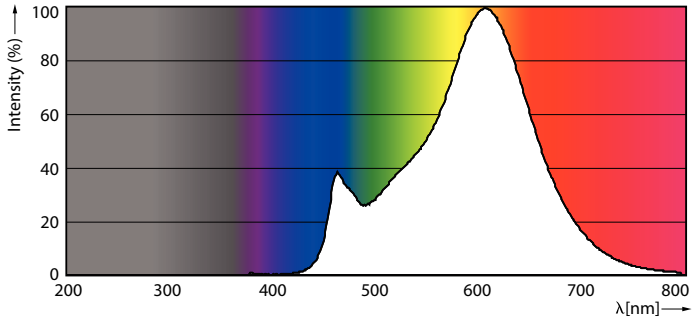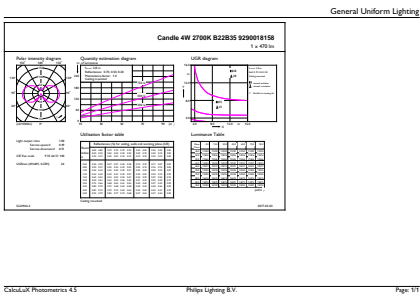

LEDbulb 40W B22 827 CL A60 ND

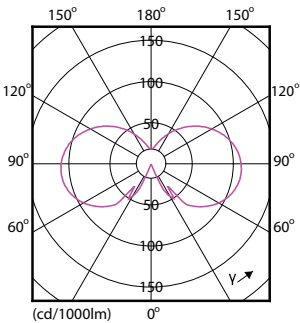


CLA LEDbulb 40W B22 827 CL A60 ND

Classic filament LED Lamps

Lifetime



LEDbulb 60W E14 827 FR B38

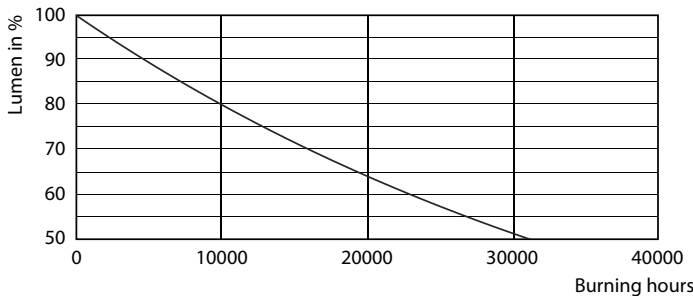

LEDbulb 60W E14 827 FR B38

