

**ModuPlug
HDC MHE 6P MC****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com**Flexible**

The four module sizes make for individual plug solutions that save a huge amount of space. The smaller pitch translates into an optimised design too.

General ordering data

Type	HDC MHE 6P MC
Order No.	1505650000
Version	Module
GTIN (EAN)	4050118314113
Qty.	1 pc(s).

**ModuPlug
HDC MHE 6P MC**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data**Dimensions and weights**

Net weight	11.58 g
------------	---------

Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

General data

Insulation resistance	$10^{12} \Omega$	Material	Polycarbonate, glass fibre reinforced
No. of poles	6	Plugging cycles	≥ 500
Pollution severity	3	Rated current (DIN EN 61984)	16 A
Rated impulse voltage (DIN EN 61984)	8 kV	Rated voltage (DIN EN 61984)	830 V
Rated voltage according to UL/CSA	600 V	Required plug-in slots	1
Series	ModuPlug	Surge voltage category	III
Type	Male	UL 94 flammability rating	V-0

PE connection data

Connection type PE	Screw connection via module frame
--------------------	-----------------------------------

Version

Conductor cross-section, max.	4 mm ²	Conductor cross-section, min.	0.5 mm ²
Stripping length, rated connection	7.5 mm	Type of connection	Crimp connection
Wire connection cross section AWG, max.	AWG 12	Wire connection cross section AWG, min.	AWG 20

Classifications

ETIM 6.0	EC002312	eClass 6.2	27-14-34-19
eClass 9.1	27-44-02-18		

Approvals

Approvals

 

**Downloads**

Brochure/Catalogue	CAT 3 HDC 17/18 EN FL FIELDWIRING EN
Engineering Data	EPLAN


ModuPlug HDC MHE 6P MC

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com


Drawings

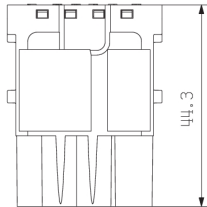


**HDC-MHE 6P-Module im IP65-Gehäuse,
Leiter H05V-K0,5:**

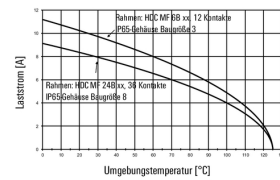


**HDC-MHE 6P-Module im IP65-Gehäuse,
Leiter H07V-K4,0:**

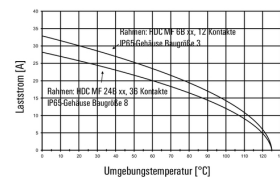

**HDC-MHE 6P-modules in the IP65-housing,
Conductor H05V-K0,5:**

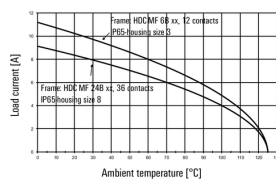

**HDC-MHE 6P-modules in the IP65-housing,
Conductor H07V-K4,0:**

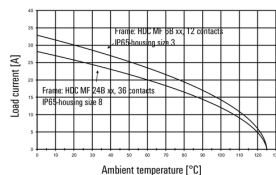

ModuPlug HDC MHE 6P MC

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Accessories

Crimp contacts HE



Crimps provide a electrical and mechanical connection between wire and contact that is both secure and reliable. The optimal crimp connection is gas-tight and corrosion-resistant.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
HDC-C-HE-SM4.0AG	1200900000	Heavy Duty Connectors, Crimp contact, HE, HEE, HQ, MixMate, Male, Conductor cross-section, max.: 4, turned, Copper alloy	4008190115906	100 pc(s).
HDC-C-HE-SM4.65AU	1116540000	Heavy Duty Connectors, Crimp contact, HE, HEE, HQ, MixMate, Male, Conductor cross-section, max.: 4.65, turned, Copper alloy	4032248897261	100 pc(s).
HDC-C-HE-SM0.5AG	1200500000	Heavy Duty Connectors, Crimp contact, HE, HEE, HQ, MixMate, Male, Conductor cross-section, max.: 0.5, turned, Copper alloy	4008190159627	100 pc(s).
HDC-C-HE-SM0.75-1.00AU	1651430000	Heavy Duty Connectors, Crimp contact, HE, HEE, HQ, MixMate, Male, Conductor cross-section, max.: 1, turned, Copper alloy	4008190400101	100 pc(s).
HDC-C-HE-SM2.5AG	1200800000	Heavy Duty Connectors, Crimp contact, HE, HEE, HQ, MixMate, Male, Conductor cross-section, max.: 2.5, turned, Copper alloy	4008190131913	100 pc(s).
HDC-C-HE-SM1.5AG	1200700000	Heavy Duty Connectors, Crimp contact, HE, HEE, HQ, MixMate, Male, Conductor cross-section, max.: 1.5, turned, Copper alloy	4008190074920	100 pc(s).
HDC-C-HE-SM0.5AU	1651420000	Heavy Duty Connectors, Crimp contact, HE, HEE, HQ, MixMate, Male, Conductor cross-section,	4008190400095	100 pc(s).

ModuPlug HDC MHE 6P MC

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Accessories

		max.: 0.5, turned, Copper alloy	
HDC-C-HE-SM2.5AU	1651450000	Heavy Duty Connectors, Crimp contact, HE, HEE, HQ, MixMate, Male, Conductor cross-section, max.: 2.5, turned, Copper alloy	4008190400125 100 pc(s).
HDC-C-HE-SM4.0AU	1651460000	Heavy Duty Connectors, Crimp contact, HE, HEE, HQ, MixMate, Male, Conductor cross-section, max.: 4, turned, Copper alloy	4008190400132 100 pc(s).
HDC-C-HE-SM0.75-1.00AG	1200600000	Heavy Duty Connectors, Crimp contact, HE, HEE, HQ, MixMate, Male, Conductor cross-section, max.: 1, turned, Copper alloy	4008190171308 100 pc(s).
HDC-C-HE-SM1.5AU	1651440000	Heavy Duty Connectors, Crimp contact, HE, HEE, HQ, MixMate, Male, Conductor cross-section, max.: 1.5, turned, Copper alloy	4008190400118 100 pc(s).