

# 4 in 1 ToughArmor

HDD BAY

MB607SP-B • 4 Bay 2.5" SATA Hard Drive & SSD  
5.25" Backplane Cage



RUGGEDIZED



NON-FLAMMABLE



FULL METAL




SUPPORT  
SATA 6Gbps



4x 2.5"



Fits 1x 5.25"  
External Bay

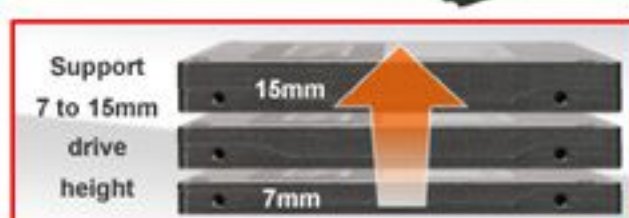

Support  
7 to 15mm  
drive  
height

15mm

7mm



SUPPORTS LOCKING CLIP



HDD IN



HDD OUT



## ToughArmor MB607SP-B Features & Specs

- Full steel construction commercially designed for Medical & Military systems, Media servers, and IPCs, approved & used by Tier 1 companies.
- Perfect for rugged applications and complies to flammability requirements
- Fits 4 x 7mm to 15mm 2.5" SAS/SATA HDD or SSD in a single external 5.25" bay for high performance RAID applications.
- Requires only a single 15pin power connectors to power all 4 bays
- Anti-Vibration Technology (AVT) - creates a safe environment for HDD or SSDs
- Active Power Technology (APT) - individual led & cooling fan only powers up if there is a drive installed in the bay
- Eagle-hook lock system keeps drives secured within the enclosure
- Removable tray system for easy maintenance
- Top Cover for the Tray Adds Extra Drive Protection.
- Supports SATA 6Gbps and hot swap
- Heavy Duty Full Steel Construction
- 40mm cooling fans with external fan controller for low, medium. or high setting.

Model Number	MB607SP-B
Color	Black
Host Interface	4 x 7pin SATA
Drive Fit	4 x 2.5" SATA I / II / III SSD or HDD (7-15mm thickness)
Device Fit	Single external half height 5.25" bay
Transfer Rate	Up to 6 Gb/sec. (depending on hard drive speed)
Insert & Extract connection Via	Direct SATA hard drive connection
Structure	Metal
Device Power	1 x 15pin SATA power port
Drive Cooling	1 x 40mm rear cooling fan + fan power switch Metal heat dispersion
Power Indicator	Solid Green LED
HDD Access Indicator	Flashing Green LED
Dimension (L x W x H)	6.70" x 5.75" x 1.63"
Weight	1.77 lbs
Package Contents	Device, user manual and screws