



**Wiha Ball End Precision Series**

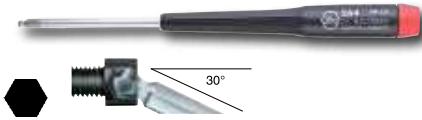

**264 Inch Ball End Hex Inch Screwdriver**  
With Precision Handle Angle entry up to 30°. Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finish.

Item	Inch	mm	Inch	mm	Inch	lbs.	Pkg.
26413	.050	40	1.6	120	4.7	.02	10
26416	1/16	50	2.0	145	5.7	.03	10
26419	5/64	50	2.0	145	5.7	.03	10
26423	3/32	50	2.0	145	5.7	.03	10
26427	7/64	60	2.4	170	6.7	.03	10
26431	1/8	60	2.4	170	6.7	.05	10
26436	9/64	60	2.4	170	6.7	.05	10
26439	5/32	60	2.4	170	6.7	.05	10

 \*Metric dimensions actual - Inch dimensions approximate



**264 Metric Ball End Hex Metric Screwdriver**  
With Precision Handle Angle entry up to 30°. Blade high alloy CVM steel.

Item	mm	Inch	mm	Inch	mm	Inch	lbs.	Pkg.
26413	1.3	.050	40	1.6	120	4.7	.02	10
26415	1.5	-	50	2.0	145	5.7	.03	10
26420	2.0	-	50	2.0	145	5.7	.03	10
26425	2.5	-	60	2.4	170	6.7	.04	10
26430	3.0	-	60	2.4	170	6.7	.05	10
26440	4.0	-	60	2.4	170	6.7	.05	10

\*Metric dimensions actual - Inch dimensions approximate



**26491 5 Piece Ball End Hex Driver Set - Metric** Angle entry up to 30°. Blade high alloy chrome-vanadium-molybdenum-steel.

Item	Ball End Hex Metric:	lbs.
26491	1.3 x 40mm 1.5, 2.0 x 50mm 2.5, 3.0 x 60mm	.31



**26490 8 Piece Ball End Hex Driver Set - Inch** Angle entry up to 30°. Blade high alloy chrome-vanadium-molybdenum steel.

Item	Hex Inch:	lbs.
26490	1/16, 5/64, 3/32 x 2.0, 7/64, 1/8, 9/64, 5/32 x 2.4"	.40



In canvas storage pouch

**26499 8 Pc. Ball End Hex Driver Set - Inch** Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished.

Item	Ball End Hex Inch:	lbs.
26499	.050 x 1.6" 1/16, 5/64, 3/32 x 2.0" 7/64, 1/8, 9/64, 5/32 x 2.4"	.62

**Wiha TORX® Precision Series**



**26792 7 Pc. TORX® Screwdriver Set** Blade high alloy chrome-vanadium-molybdenum steel.

Item	TORX®:	lbs.
26792	T5, T6, T7, T8 x 40mm T9, T10 x 50mm T15 x 60mm	.33

**Wiha TORX® Precision Series**



**267 TORX® Screwdriver, With Precision Handle** Blade high alloy chrome-vanadium-molybdenum steel.

Item	No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
26701	T1	40	1.6	120	4.7	.01	10	
26702	T2	40	1.6	120	4.7	.02	10	
26703	T3	40	1.6	120	4.7	.02	10	
26704	T4	40	1.6	120	4.7	.02	10	
26705	T5	40	1.6	120	4.7	.02	10	
26706	T6	40	1.6	120	4.7	.02	10	
26707	T7	40	1.6	120	4.7	.02	10	
26708	T8	40	1.6	120	4.7	.03	10	
26709	T9	50	2.0	145	5.7	.03	10	
26710	T10	50	2.0	145	5.7	.03	10	
26715	T15	60	2.4	170	6.7	.05	10	
26720	T20	60	2.4	170	6.7	.05	10	

\*Metric dimensions actual - Inch dimensions approximate



**26790 6 Pc. TORX® Screwdriver Set** Blade high alloy chrome-vanadium-molybdenum steel.

Item	TORX®:	lbs.
26790	T6, T7, T8 x 40mm T9, T10 x 50mm T15 x 60mm	.30

**26791 Set 8 Pcs. TORX® Screwdriver Set**

Item No.	T1, T2, T3, T4,
26791	T5, T6, T7, T8



**26799 8 Pc. TORX® Screwdriver Set** Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished. In canvas storage pouch

Item	TORX®: T3, T4, T5,	lbs.
26799	T6, T7, T8 x 40mm T9 x T10 x 50mm	.50