

Hole knockouts on each side of fitting




CHARGE TEST

PERFECT FOR OFFICE, COMMERCIAL AND INDUSTRIAL APPLICATIONS

MAINTAINED LED EMERGENCY EXIT BOX SIGN WITH SIGNS DIRECTIVE DOWN ARROW LEGEND

Low energy alternative to standard emergency exit signs.

- Steel construction
- 3 hour maintained mode as standard which can also be configured for non maintained operation
- Facility for remote switching
- Interchangeable polycarbonate signs directive down arrow exit legend included
- Diffuser on base: for added downward illumination of exit path
- Long life energy efficient LED light source eliminates lamp replacement cycle without compromising panel visibility distance
- Full range of alternative legend directional panels available
- LED charge light and battery test button
- Viewing distance: 34m
- 55 lumens in mains mode

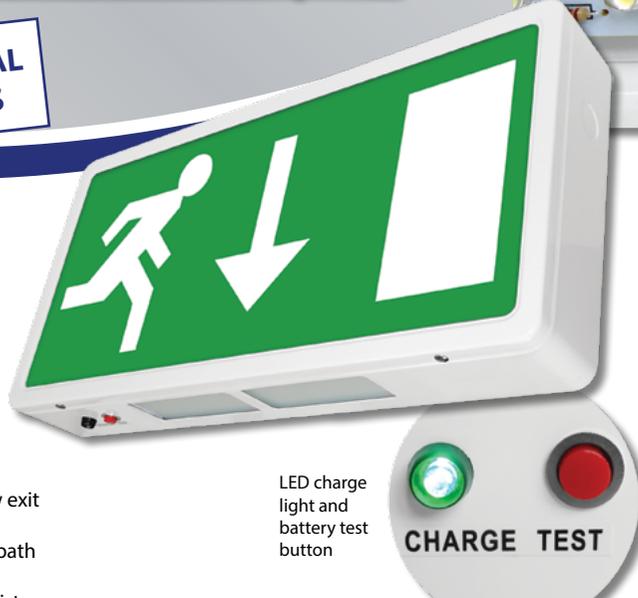

LED charge light and battery test button



CHARGE TEST




LED array in top of fitting



EternaPro
LED
5 YEAR
Warranty*

• **EXIT3MLED** = M.O.M: 6 / O.P.Q: 6
• **Legends** = M.O.M: 1 / O.P.Q: 100

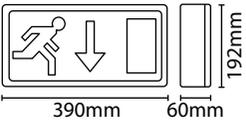

EBLGDU



ISOEBLGDD

Code	Colour	Wattage	Avg. Rated Life (Hrs)	IP Rating
EXIT3MLED	White	4W	30,000 hrs	IP20
EBLGDL	Signs Directive Left Arrow Legend			
EBLGDR	Signs Directive Right Arrow Legend			
EBLGDU	Signs Directive Up Arrow Legend			
ISOEBLGDL	ISO 7010 Left Arrow Legend			
ISOEBLGDR	ISO 7010 Right Arrow Legend			
ISOEBLGDU	ISO 7010 Up Arrow Legend			
ISOEBLGDD	ISO 7010 Down Arrow Legend			

*Subject to terms & conditions