


 
 




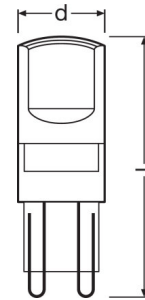









P PIN 20 1.9 W/2700 G9



Product code 4058075811454

	G9
	46.0 mm
	15.0 mm
	–
W	1.90 W
lm	200 lm
	200 lm
	–
	200 lm
	–
cd	–
K	2700 K
COLOUR	Warm White
R_a	≥80
t [h]	15000 h
	No
V	220...240 V
Hz	50...60 Hz

	100000
	300.00 °
	< 0.50 s
	< 0.5 s
	–
Hg	0.0 mg
	A++
	2 kWh/1000h

