


 
 


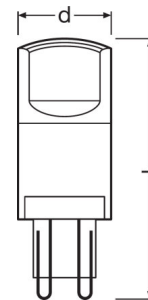











P PIN 40 3.8 W/4000 G9



Product code 4058075812710

	G9
	58.0 mm
	20.0 mm
	–
W	3.80 W
lm	470 lm
	470 lm
	–
	470 lm
	–
cd	–
K	4000 K
COLOUR	Cool White
R_a	≥80
t [h]	15000 h
	No
V	220...240 V
Hz	50...60 Hz

	100000
	300.00 °
	< 0.50 s
	< 0.5 s
	–
Hg	0.0 mg
	A++
	4 kWh/1000h

