

ATEX-
FL4

UNILITE ZONE 0 INTRINSICALLY SAFE FLASHLIGHT

Upgraded


 LIGHT BY
CREE
 LEDs

ATEX


 6-69
 HOURS
 RUNTIME

 235
 METRE
 BEAM RANGE

 150
 LUMENS
 OUTPUT

 IP67
 DUST+WATER
 PROOF


REACH

CE

RoHS




RUBBERISED HEAD



ZONE 0 ATEX COMPLIANT



ELECTRONIC TACTICAL SWITCH

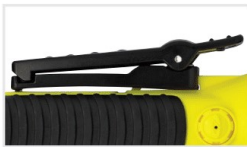

POCKET CLIP INCLUDED

- » 150 Lumen white CREE LED
- » ATEX Zone 0 gas compliant
- » Safety release valve to release hydrogen gases
- » Chemical and corrosion resistant
- » Rubberised head & handle for greater durability
- » Industrial strength polycarbonate housing
- » Detachable pocket clip included for hands free use
- » Safety locking battery compartment
- » Optional brackets available for helmets
- » IP67 dust and waterproof
- » 3m submersible

BATTERY 4 x 1.5v AA Alkaline Batteries (not included)
WEIGHT 115g (without batteries)
DIMENSION 174 x 47 x 47mm