

UNILITE USB RECHARGEABLE INSPECTION LIGHT

PS-IL5R



- » 9x White Samsung SMD LEDs - 500 lumen
- » Additional 200 lumen torch in the head
- » Ultra strength aluminium and polycarbonate housing
- » Integral pocket clip and strong magnets for hands-free use
- » DC-USB charging cable included for portable non-static charging
- » Red-to-Green charging indicator light
- » Operating Temperature: -5 °C to +40 °C
- » Protection Class: IP54 (do not submerge)
- » Impact Resistant to 1m

3-7
HOURS
RUNTIME

52
METRE
BEAM RANGE

500
LUMENS
OUTPUT

IP54
DUST & WATER
RESISTANCE


BATTERY 3.7v 2500 mAh lithium-ion rechargeable battery (included)

WEIGHT 200g (not inc cable)

DIMENSION 180 x 35 x 32 mm



RED-TO-GREEN INDICATOR LIGHT

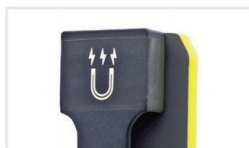

USEFUL MAGNET AND HOOK



COMPACT HANDHELD SIZE



200 LUMEN TORCH HEAD



PROFESSIONAL LIGHTING GUIDE