

UNILITE USB RECHARGEABLE PENLIGHT

UK-P2R

NEW



2-16
HOURS
RUNTIME

35
METRE
BEAM RANGE

210
LUMENS
OUTPUT

IPX4
WATER
RESISTANCE

- » 210 Lumen white LG LED
- » Flood to Spot easy push/pull focus control
- » Optical lens technology for smooth beam
- » Strong die cast aluminium housing
- » 3 Stage dimming - High / Medium / Low
- » Useful pocket clip for easy attachment
- » Strong magnet within the tactical switch
- » Impact resistant 1m
- » Protective sheath covers micro-USB port
- » Red-to-Green charging indicator light
- » Micro-USB charging cable (included)
- » Presented in a clear hard display case

BATTERY 1 x 3.7v 320mAh 10440 Li-ion Battery (included)
WEIGHT 52g (with battery)
DIMENSION 18 x 18 x 128mm



USB
CHARGING




STRONG MAGNET WITHIN SWITCH



MICRO-USB CHARGING



SMALL COMPACT SIZE

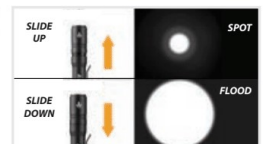

EASY SLIDE FLOOD TO SPOT FOCUS