

BE-02+


UNILITE USB RECHARGEABLE BEANIE LIGHT

NEW COLOURS


Orange: BE-02+0 / **Black:** BE-02+ / **Yellow:** BE-02+Y

**ALSO IDEAL AS A
HANDY KEY-FOB**
USB
CHARGING

SAMSUNG
LED CHIP

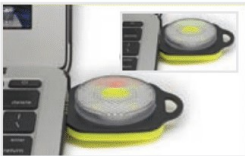
2½-6½
HOURS
RUNTIME

13
METRE
BEAM RANGE

150
LUMENS
OUTPUT

IPX5
WATER
RESISTANCE

**COMFORTABLE KNITTED BEANIE -
ONE SIZE FITS ALL**

**HIGH POWERED
150 LUMEN OUTPUT**

**CHARGE DIRECTLY FROM
USB PORT - RED TO GREEN LIGHTS**

**SUPPLIED READY
MERCHANTISED**

- » High quality warm knitted beanie hat with integrated USB rechargeable LED light
- » 4 x high powered cool white 6500k Samsung SMD LEDs - 150 lumen
- » 420mAh Lithium-polymer battery
- » Gives you between 2.5 and 6.5 hours of light off one charge
- » Light can easily be removed from the hat and charged directly through a USB port
- » Can be fully charged in 4 hours
- » Press once to turn on and toggle between 3 light intensity levels. HIGH > LOW > 2 Hz FLASH > OFF
- » Comfortable knitted Beanie, one size fits all
- » Material: 35% acrylic 65% polyester, machine washable at 30°
- » Ideal for: Runners, Walkers, Camping, Plumbers, Electricians, Tradesman and Contract Engineers

BATTERY 1 x 420 mAh Li-polymer Battery (included)
WEIGHT 125g (with beanie)
DIMENSION Headlight: 74 x 41 x 15mm - Beanie: W 250 x H 220 mm