
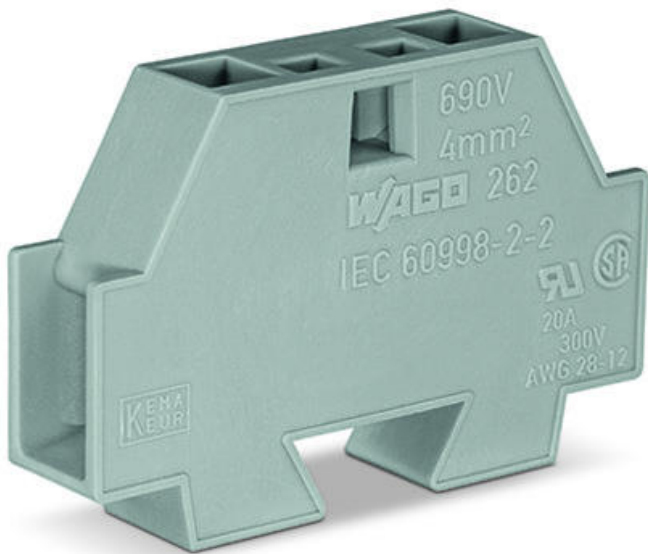
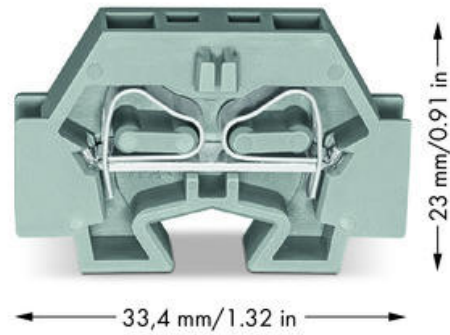


Data sheet | Item number: 262-321

Space-saving, 2-conductor end terminal block; without protruding snap-in mounting foot; for terminal strips with snap-in mounting feet

www.wago.com/262-321

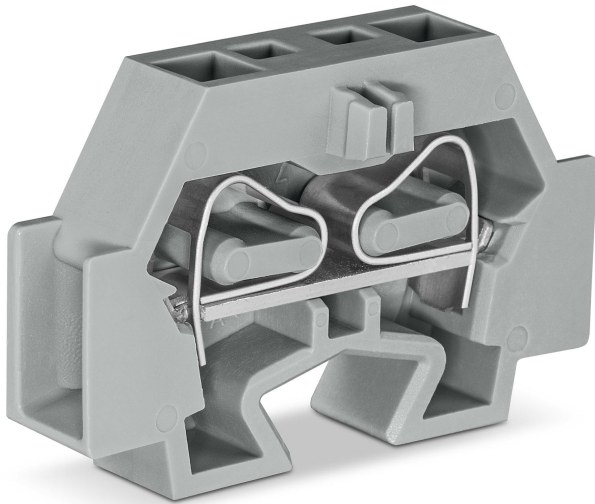

Data
Electrical data



Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	630 V
Rated impulse voltage (III / 3)	8 kV
Rated current	24 A
Legend (ratings)	(III / 3) \triangleq Overvoltage category III / Pollution degree 3

Connection data

Connection technology	CAGE CLAMP®
Actuation type	Operating tool
Connectable conductor materials	Copper Aluminum
Solid conductor	0.08 ... 4 mm ² / 28 ... 12 AWG
Fine-stranded conductor	0.08 ... 4 mm ² / 28 ... 12 AWG
Strip length	9 ... 10 mm / 0.35 ... 0.39 Inch
Total number of connection points	2
Total number of potentials	1
Number of levels	1
Type of wiring	Side-entry wiring

Geometrical Data

Width	7 mm / 0.276 Inch
Height from the surface	23 mm / 0.906 Inch
Depth	33.5 mm / 1.319 Inch

Mechanical data

Design	horizontal
Mounting type	Snap-in mounting foot
Marking level	Side marking




Material Data

Color	gray
Fire load	0.063 MJ
Weight	3.661 g




Commercial data

Packaging type	BOX
Country of origin	CN
GTIN	4044918640381
Product Group	9 (Std. Chassis Mt. Blocks)

Country specific Approvals


Logo	Approval	Certificate name
	CCA DEKRA Certification B.V.	NTR-NL 6510
	CCA DEKRA Certification B.V.	2110272.03
	CSA DEKRA Certification B.V.	70010891

Ship Approvals

Logo	Approval	Certificate name
	ABS American Bureau of Shipping	14-HG1241539-PDA
	BV Bureau Veritas S.A.	07436/E0 BV
	LR Lloyds Register	91/20242(E6)



UL-Approvals

Logo	Approval	Certificate name
	UR Underwriters Laboratories Inc.	E45172

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG
Hansastr. 27
32423 Minden
Phone: +49571 887-0 | Fax: +49571 887-169
Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?
We are always happy to take your call at 01788 568 008.