




Quality Products. Service Excellence.

Universal Rack Shelf *RAS Series*

Up to 200 lbs Weight Capacity

Features

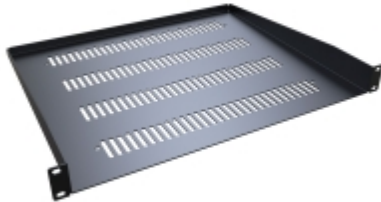

- Constructed of 14 or 16 gauge steel.
- Universal design mounts to any standard EIA compliant rack or cabinet.
- Allows easy rack mounting of equipment or items that do not have rack mounting capabilities.
- Mounts to rack rails either as an internal shelf or external shelf/work area.
- Available in either vented or solid versions.
- Rugged textured black powder paint finish.
- TAA Compliant
- RoHS and REACH compliant
- Manufactured in North America



Accessories

- Mounting Hardware
- Hook and Loop Roll

19 Inch Mounting Shelves

Part No. Vented	Part No. Solid (Un-Vented)	Mounting Dimensions			Rack Units	Stiffener Lip(s) Folded	Suggested Load Capacity
		Height	Width	Depth			
RASV190107UBK1	RASU190107UBK1	1.75	19.00	7.00	1U	Up (Front & Back)	40
RASV190107DBK1	RASU190107DBK1	1.75	19.00	7.00	1U	Down (Front & Back)	40
RASV190110BK1	RASU190110BK1	1.75	19.00	10.00	1U	Up (Back Only)	40
RASV190112BK1	RASU190112BK1	1.75	19.00	12.00	1U	Up (Back Only)	40
RASV190115BK1	RASU190115BK1	1.75	19.00	15.00	1U	Up (Back Only)	40
RASV190120BK1	RASU190120BK1	1.75	19.00	20.00	1U	Up (Back Only)	40
RASVL190314BK1	RASUL190314BK1	3.50	19.00	14.50	2U	Up (Back Only)	80
RASV190312BK1	RASU190312BK1	3.50	19.00	12.00	2U	Up (Back Only)	100
RASV190315BK1	RASU190315BK1	3.50	19.00	15.00	2U	Up (Back Only)	100
RASV190318BK1	RASU190318BK1	3.50	19.00	18.00	2U	Up (Back Only)	100
RASV190320BK1	RASU190320BK1	3.50	19.00	20.00	2U	Up (Back Only)	100
RASVL190514BK1	RASUL190514BK1	5.25	19.00	14.50	3U	Up (Back Only)	80
RASV190515BK1	RASU190515BK1	5.25	19.00	15.00	3U	Up (Back Only)	200
-	RASU190516BK1	5.25	19.00	16.00	3U	Up (Back Only)	200
-	RASU190518BK1	5.25	19.00	18.00	3U	Up (Back Only)	200
-	RASU190520BK1	5.25	19.00	20.00	3U	Up (Back Only)	200
-	RASU190522BK1	5.25	19.00	22.00	3U	Up (Back Only)	200
-	RASU190524BK1	5.25	19.00	24.00	3U	Up (Back Only)	200
RASV190715BK1	RASU190715BK1	7.00	19.00	15.00	4U	Up (Back Only)	200
RASV190720BK1	RASU190720BK1	7.00	19.00	20.00	4U	Up (Back Only)	200

Tested to nearly double the suggested load rating.

23 Inch Mounting Shelves

Part No.	Part No.	Mounting Dimensions			Rack	Stiffener Lip(s)	Suggested
----------	----------	---------------------	--	--	------	------------------	-----------

Part No.	Part No.	Height	Width	Depth	Units	Stiffness	Load Capacity
Vented	Solid	Height	Width	Depth	Units	Folded	Load Capacity
RASV230515BK1	RASU230515BK1	5.25	23.00	15.00	3U	Up (Back Only)	200
-	RASU230520BK1	5.25	23.00	20.00	3U	Up (Back Only)	200

Tested to nearly double the suggested load rating.

Tags: **Cantilevered Shelf, 2-Post Shelf**

Data subject to change without notice

© 2018. Hammond Manufacturing Ltd. All rights reserved.