



 
 
UFT Ultra-Fine Tweezer Cartridges are compatible with CV-5200, CV-500 Systems and CV-H4-UFT Ultra-Fine Tweezer Hand piece.

Temperature	CV-Serie	Application
675 °F/357 °C	UFT-6	Temperature Sensitive
775 °F/412 °C	UFT-7	Most Standard

 
 
 
Please note the above temperatures are the maximum temperatures of the heater. The idle temperature is dependent on the geometry of the cartridge (up to 15 °C lower).

These tips will provide data via the CV power supplies, but due to the nature of their application the Connection Validation function is not required and therefore not enabled. - All tweezer cartridges are sold per pair!

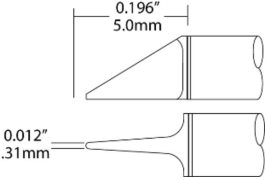
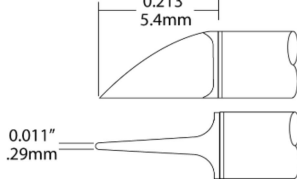
Ultra-Fine Tweezer Cartridge - Chisel

	UFT-6CH9006S	(W x L) 0.6 x 9 mm (.0024" x .035"), Sold per pair
	UFT-7CH9006S	
	UFT-6CH9008S	(W x L) 0.8 x 9 mm (.031" x .035"), Sold per pair
	UFT-7CH9008S	

Ultra-Fine Tweezer Cartridge - Conical

	UFT-6CN5502R	Conical, Bent, for work under a microscope, (Ø x L) 0.2 x 5.6 mm (0.008" x 0.220") Sold per pair
	UFT-7CN5502R	
	UFT-6CN5504R	Conical, Bent, for work under a microscope, (Ø x L) 0.4 x 5.6 mm (0.16" x 0.220"), Sold per pair
	UFT-7CN5504R	
	UFT-6CN8004S	Conical, (Ø x L) 0.4 x 8.7mm (0.16" x 0.343"), Sold per pair
	UFT-7CN8004S	

Ultra-Fine Tweezer Cartridge - Power Wedge

	UFT-6PW3150S	Power Wedge, two-way use, tip and long side, (Ø x L) 0.31 x 5.0 mm (0.012" X 0.196"), Sold per pair
	UFT-7PW3150S	
	UFT-6PW2954C	Power Wedge, two-way use, tip and long side, (Ø x L) 0.29 x 5.4 mm (0.011" X 0.213"), Sold per pair
	UFT-7PW2954C	