

### Convertible Snap Ring Pliers 18400

- Overall Length: 7", width: 5", thickness: 0.91"
- Convertible retaining ring pliers
- Carbon steel with coated grip handles
- 4 Sets of tips included:
- 1.2mm - straight and 90° (black)
- 1.8mm - straight and 90° (chrome)

UPC	Master	Inner
8-02090-18400-0	48	8



### Snap Ring Plier Set 18402


- For use with both internal and external snap rings
- Includes 4 interchangeable tips: (2) straight, (1) 90° and (1) 45°
- Comfort grip handles
- Effective range: 10 - 50 mm (3/8" x 2")

UPC	Master	Inner
8-02090-18402-4	60	6



### 24 in. Cable Cutter 11424

- Max Cutting Diameter: 1-5/16" (3.33cm)
- Max cutting load: 673N (151.3 lbs.)
- Drop forged chrome-moly jaws
- Heat treated handles for added strength and durability

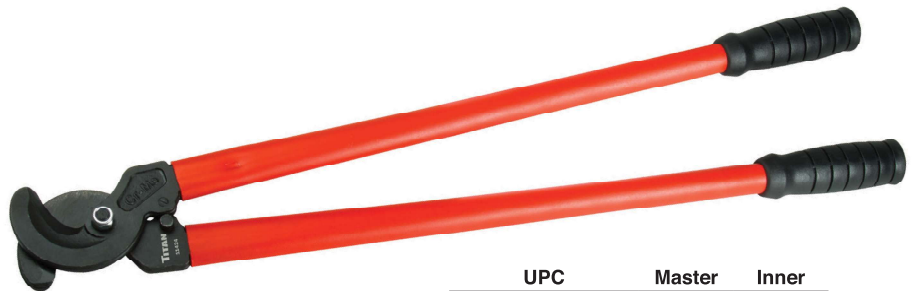

UPC	Master	Inner
8-02090-11424-3	8	4

### Compound Action Cable Cutters 11470

- 10" overall height
- Meets or exceeds federal ANSI specification B107.16-1998
- Induction hardened, serrated blades
- Compound leverage cutters
- Quick and simple spring-free automatic latch design
- Cuts copper and aluminum electric cable up to 1/2" diameter
- Drop forged Chrome-Molybdenum Alloy steel blades are hardened to help maintain cutting edges
- New quick and simple spring-free automatic latch design (one hand release) provides safety and convenience
- Cuts the following: Copper and aluminum electric cable up to 2AWG (14mm) or 1/2" (12mm) diameter
- Includes reusable holster



UPC	Master	Inner
8-02090-11470-0	36	6