
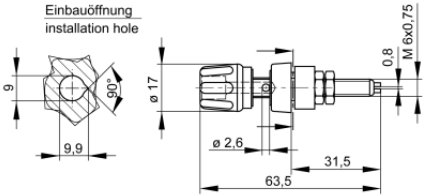


## Sockets

### PKNI 20 B



Product	PKNI 20 B
description	Pole terminal with claw edge, captive insulated head and insulated ring. 6 mm diameter nickel-plated brass threaded bolt with 2.6 mm diameter transverse hole. For insulated non-rotating installation in equipment chassis and switch panels up to 3.5 mm wall.
article-no. / *colour	9301441xx  <div style="text-align: right; border: 1px solid black; padding: 2px;"><b>Ni</b></div>
drawing	
technical data	
connection	M6 thread, solder connection
rated voltage <sup>(1)</sup>	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O <sup>(3)</sup>
rated current <sup>(1)</sup> (consider derating curve)	63 A
material socket	brass, nickel plated
housing material	PA
temperature range acc. To IEC61010 <sup>(2)</sup>	-25 °C to +100 °C
inflammability class acc. to UL 94 (only valid for basic material of housing)	V-2
standard	IEC 61010

4 mm system

<sup>(1)</sup> for normal environmental conditions -5°C to +40°C

<sup>(2)</sup> contact the manufacturer for applications at deviating temperature ranges

<sup>(3)</sup> Other circuits that are not directly connected to mains  
stand: 26.07.2018