


Plugs

KST WS 14/4

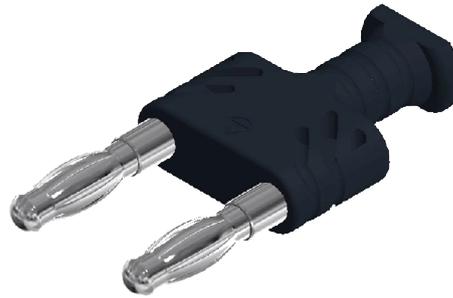

Product	KST WS 14/4
description	Jumper plug with spring-loaded 4 mm plugs and one 4 mm unsprung socket for connection with all 4 mm spring-loaded plugs that are not contact-protected. Shatter-proof insulation.
article-no. / *colour	9722651xx ● 00 black Ni
technical data	
rated voltage ⁽¹⁾	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽³⁾
rated current ⁽¹⁾ (consider derating curve)	32 A
material plug	brass, nickel plated
housing material	PBT
temperature range acc. To IEC61010 ⁽²⁾	-15 °C to 70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB
standard	IEC 61010

4 mm system

⁽¹⁾ for normal environmental conditions -5°C to +40°C

⁽²⁾ contact the manufacturer for applications at deviating temperature ranges

⁽³⁾ Other circuits that are not directly connected to mains

stand: 16.07.2018