

 
SxP Soldering & Rework Cartridges




SxP SOLDERING & REWORK CARTRIDGES

Compatible with: MFR-1110, MFR-1161, MFR-1351, MFR-2211, MFR-2241 Systems and MFR-H1-SC hand-piece


CHISEL




SFP-CH10
STP-CH10
SCP-CH10

 


SFP-CH15
STP-CH15
SCP-CH15

 


SFP-CHB15
STP-CHB15
SCP-CHB15

 


SFP-CH20
STP-CH20
SCP-CH20

 


SFP-CHL20
STP-CHL20
SCP-CHL20

 


SFP-CH25
STP-CH25
SCP-CH25

 

SFP-CH30
STP-CH30
SCP-CH30

 


SFP-CH35
STP-CH35
SCP-CH35

 


SFP-CH50
STP-CH50
SCP-CH50

 HOOF




STP-WV20
SFP-WV20
SCP-WV20

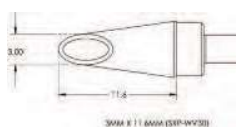


STP-WV30
SFP-WV30
SCP-WV30

 
CONICAL




SFP-CN04
STP-CN04
SCP-CN04

 


SFP-CNB04
STP-CNB04
SCP-CNB04

 

SFP-CNL04
STP-CNL04
SCP-CNL04

 

SFP-CN05
STP-CN05
SCP-CN05

 


SFP-CNB05
STP-CNB05
SCP-CNB05




SFP-CNL06
SCP-CNL06

 BEVEL




SFP-BVL10
STP-BVL10
SCP-BVL10

 


SFP-DRH05
STP-DRH05
SCP-DRH05

 
HOOF




SFP-DRH610
STP-DRH610
SCP-DRH610

 

SFP-DRH15
STP-DRH15
SCP-DRH15

 


SFP-DRH615
STP-DRH615
SCP-DRH615

 

SFP-DRH35
STP-DRH35
SCP-DRH35

 KNIFE



SFP-DRK50
STP-DRK50
SCP-DRK50

F = FR4 / Fiberglass, for most standard applications T = Temperature Sensitive C = Ceramic for high thermal demand applications.