


KEMET, FX5, Flex Suppressors, Commercial Grade

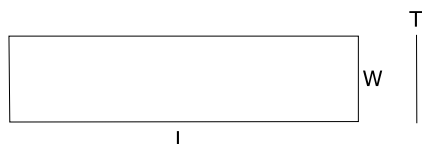

Dimensions

Sheet Size	240x50mm
L	240mm NOM
W	50mm NOM
T	0.075mm NOM

Packaging Specifications

Tape Description:	No Adhesive Tape
Weight:	2.97 kg

General Information

Series:	FX5
Style:	Sheet
Description:	Flex Suppressor High Permeability Type
Features:	High Permeability Type
RoHS:	Yes
Qualifications:	UL94 HB, UL File No. E176124
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Specifications

Temperature Range:	-40/+105C
Magnetic Permeability:	150 TYP At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.3 Atm TYP