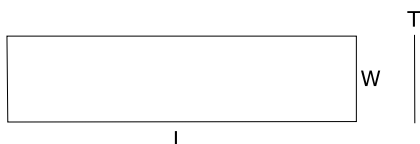


## KEMET, FF1, Flex Suppressors, Commercial Grade

**Dimensions**

Sheet Size	240x50mm
L	240mm NOM
W	50mm NOM
T	0.05mm NOM

**Packaging Specifications**

Tape Description:	Without PET Tape (Txx00)
Tape Thickness:	0.03mm
Weight:	2.0424 kg

**General Information**

Series:	FF1
Style:	Sheet
Description:	Flex Suppressor Flame Retardant Type
Features:	Flame Retardant Type
RoHS:	Yes
Qualifications:	UL94 V-0, UL File No.E176124, AEC-Q200
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free

**Specifications**

Temperature Range:	-40/+105C
Magnetic Permeability:	100 TYP At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.1 Atm TYP
Conductivity:	1.8 W/m K
Tensile Strength:	10.8 MPa MIN