


KEMET, RM4A, Flex Suppressors, Commercial Grade

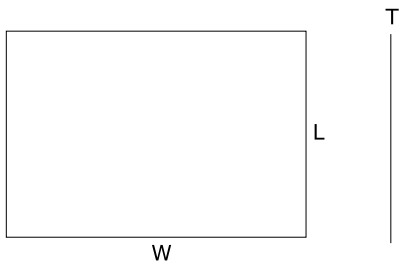

General Information	
Series:	RM4A
Style:	Sheet
Description:	Flex Suppressor Magnetic Sheet For RFID
Features:	High Magnetic Permeability Type, Low Magnetic Loss Type
RoHS:	Yes
Environment:	Halogen Free, PVC Free, Lead Free, RoHS Compliant

Dimensions	
Sheet Size	220x185mm
L	220mm NOM
W	185mm NOM
T	0.2mm NOM

Specifications	
Temperature Range:	-40/+85C
Magnetic Permeability:	50 TYP at 13.56MHz
Effective Frequency:	13.56 Mhz
Resistance:	10 MOhms MIN
Specific Gravity:	3.6 Atm TYP

Packaging Specifications	
Tape Description:	Without PET Tape (Txx00)
Tape Thickness:	0.03mm
Weight:	30.96 g