



## 57CG Standard Pliers

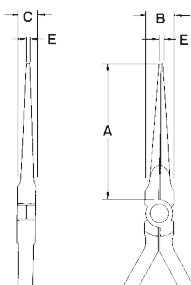

- Standard pliers
- For firm gripping and looping of wire
- Fine serrated jaw and coil spring
- Forged alloy steel construction, precision machining and scientific proportioning
- Red plastic-coated cushion grip provides maximum leverage

| Catalog Number | UPC Number   | Packed | Length (inch) | Length (mm) | A (inch) | A (mm) | B (inch) | B (mm) | C (inch) | C (mm) | E (inch) | E (mm) | Pack weight (lb) | Pack weight (g) | Shelf pack |
|----------------|--------------|--------|---------------|-------------|----------|--------|----------|--------|----------|--------|----------|--------|------------------|-----------------|------------|
| 57CGV          | 037103481658 | Carded | 5 11/16       | 144         | -        | -      | 15/32    | 12     | 1/4      | 6      | 5/64     | 2      | 20.8             | 590             | 6          |


## 51NCG, 52NCG Firm Gripping and Looping Pliers

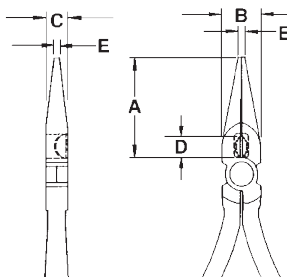

- For firm gripping and looping of wire
- Serrated jaw
- Forged alloy steel construction, precision machining and scientific proportioning
- Side cutter feature
- Red plastic-coated cushion grip provides maximum leverage
- 52NCGV without side cutter

| Catalog Number | UPC Number   | Packed | Length (inch) | Length (mm) | A (inch) | A (mm) | B (inch) | B (mm) | C (inch) | C (mm) | D (inch) | D (mm) | E (inch) | E (mm) | Pack weight (lb) | Pack weight (g) | Shelf pack |
|----------------|--------------|--------|---------------|-------------|----------|--------|----------|--------|----------|--------|----------|--------|----------|--------|------------------|-----------------|------------|
| 51NCG          | 037103481528 | Boxed  | 6             | 152         | 1 7/8    | 48     | 11/16    | 17     | 3/8      | 10     | 1/2      | 13     | 3/32     | 2.4    | 36.6             | 1038            | 6          |
| 51NCGV         | 037103212887 | Carded | 6             | 152         | 1 7/8    | 48     | 11/16    | 17     | 3/8      | 10     | 1/2      | 13     | 3/32     | 2.4    | 36.6             | 1038            | 6          |
| 52NCGV         | 037103212931 | Carded | 6             | 152         | 1 7/8    | 48     | 11/16    | 17     | 3/8      | 10     | 1/2      | 13     | 3/32     | 2.4    | 36.6             | 1038            | 6          |

## 59NCG Electricians Chain Nose Pliers

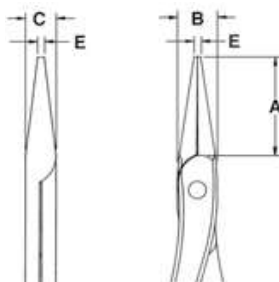

- Electrician's chain nose pliers
- Serrated jaw for gripping and high leverage
- Forged alloy steel construction, precision machining and scientific proportioning
- Offers long reach
- Red plastic-coated cushion grip provides maximum leverage

| Catalog Number | UPC Number   | Packed | Length (inch) | Length (mm) | A (inch) | A (mm) | B (inch) | B (mm) | C (inch) | C (mm) | E (inch) | E (mm) | Pack weight (lb) | Pack weight (g) | Shelf pack |
|----------------|--------------|--------|---------------|-------------|----------|--------|----------|--------|----------|--------|----------|--------|------------------|-----------------|------------|
| 59NCG          | 037103213730 | Boxed  | 8             | 200         | 1 1/2    | 32     | 9/16     | 14     | 15/32    | 12     | 3/32     | 2.4    | 44.5             | 1262            | 6          |