

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0781201207](#)
Status: **Active**
Overview: Slim-Grid Board-to-Board Connectors
Description: Slim-Grid Receptacle, 12 Circuits, Surface Mount, Vertical, 0.05µm Gold (Au) Plated, Tube, Lead-Free

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification 781200001-000 \(PDF\)](#) [Product Literature \(PDF\)](#)
[Packaging Specification 781200001-000 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179


General

Product Family PCB Receptacles
 Series [78120](#)
 Application Board-to-Board, Signal
 Comments 4.3 Amps per Pole with only 1 contact powered up

1.4 Amps per Pole with max contacts powered up
 Overview [Slim-Grid Board-to-Board Connectors](#)
 Product Literature Order No 987651-5972
 Product Name Slim-Grid
 UPC 889056864961

Physical

Circuits (Loaded) 12
 Circuits (maximum) 12
 Color - Resin Black
 Durability (mating cycles max) 500
 Flammability 94V-0
 Glow-Wire Capable No
 Guide to Mating Part Yes
 Keying to Mating Part None
 Lock to Mating Part Yes
 Material - Metal Copper Alloy
 Material - Plating Mating Gold
 Material - Plating Termination Matte Tin
 Material - Resin Liquid Crystal Polymer
 Net Weight 0.171/g
 Number of Rows 2
 Orientation Vertical
 PCB Locator No
 PCB Retention None
 Packaging Type Tube
 Pitch - Mating Interface 1.27mm
 Pitch - Termination Interface 1.27mm
 Plating min - Mating 0.051µm
 Plating min - Termination 2.540µm
 Polarized to Mating Part No
 Polarized to PCB No
 Temperature Range - Operating -55° to +105°C
 Termination Interface: Style Surface Mount
 Unmated Height 4.51mm

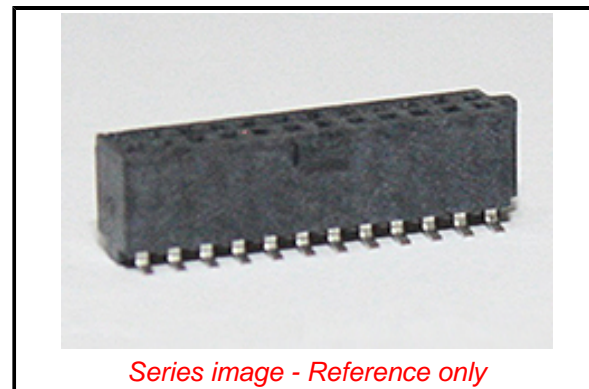

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Green Image
 ELV Not Relevant
 RoHS Phthalates Not Contained

Search Parts in this Series

[78120](#) Series

Mates With

Slim-Grid Headers [87933](#) , [200989](#) , [201021](#) , [201022](#) , [201173](#)

Electrical

Current - Maximum per Contact

1.4A

Voltage - Maximum

125V AC

Material Info**Reference - Drawing Numbers**

Packaging Specification

781200001-000

Product Specification

781200001-000

Sales Drawing

781200001-000

This document was generated on 08/03/2018

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION