

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010561](#)
Status: **Active**
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect Crimp Contact Insert, Male, 20-Pole, 16A, for Turned Crimp Contacts, Size «34.2x29.2»

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E249674

General

Product Family Industrial Connectors / Enclosures
 Series [93601](#)
 Component Size «34.2x29.2»
 Component Type Inserts - Crimp Contact
 Exclude SD Check Yes
 Insert Series S-M16/20
 Overview [GWconnect Heavy Duty Connectors \(HDC\)](#)
 Product Category Heavy Duty Connectors
 Product Name GWconnect
 Standard CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
 UPC 887191834887

Physical


Durability (mating cycles max) 500
 Flammability UL 94V-0
 Gender Male
 Insert Color Grey
 Material - Insert Polycarbonate
 Net Weight 13.700/g
 Number of Rows 5
 Packaging Type Bag
 Polarized to Mating Part Yes
 Poles 20
 Temperature Range - Operating -40°C to +125°C

Electrical

Current - Maximum per Contact 16.0A
 Voltage - Maximum 400V

Material Info

Engineering Number 7720.3356.0

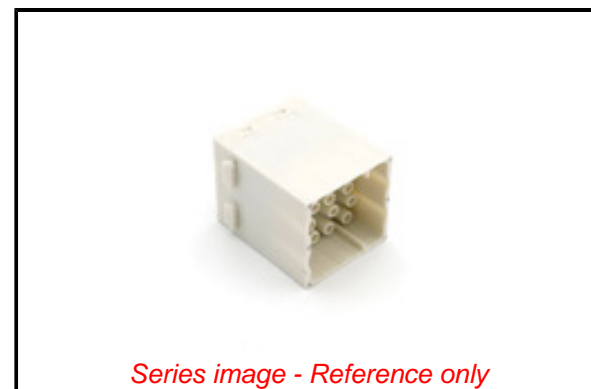

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[93601](#) Series

Mates With

[93601-0560](#) Female Crimp Contact Insert

Use With

Turned Crimp Contacts - Male