

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200700156](#)
Status: **Active**
Overview: Brad Micro-Change (M12) Connectors
Description: Micro-Change (M12) Receptacle, 4 Poles, M12x1 and PG9 Threads, Male (Straight) to 22 AWG Leads, 0.30m (11.81") Length

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Receptacles
 Series [120070](#)
 IP Rating IP67
 NEMA Rating NEMA 6
 Overview [Brad Micro-Change \(M12\) Connectors](#)
 Product Name Micro-Change (M12)
 Type Single Ended (pigtail)
 UPC 78678838215

Physical


Coupling Type External Thread
 Gender Male
 Keyway Single
 Length 0.30m
 Material - Component Nickel-plated Brass
 Mounting Thread Size PG9
 Net Weight 18.597/g
 Orientation Straight
 Panel Mount Front
 Poles 4
 Temperature Range - Operating -20°C to +80°C
 Wire Size AWG 22
 Wire/Cable Type Leads, UL 1061

Electrical

Current - Maximum per Contact 4.0A
 Voltage - Maximum 250V AC/DC

Material Info

Engineering Number 8R4J36E03C3003

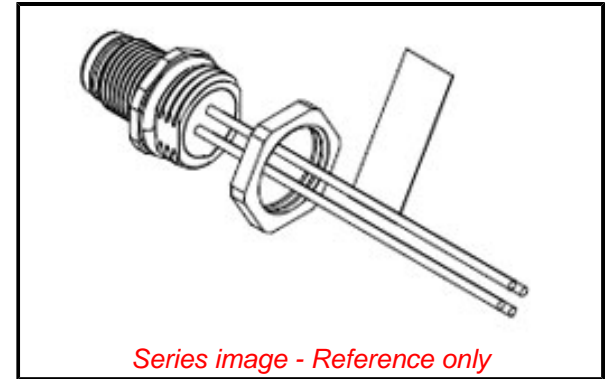

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)*

REACH SVHC

Contained Per - ED/01/2018 (15 January 2018)*
 2,4-Di-tert-butyl-6-(5-chlorobenzotriazol-2-yl)p

Halogen-Free

Status

Not Low-Halogen*

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

CUST_NOTE	*Product contains part(s) with customer managed
CUST_NOTE1	EHS data. These part(s) are excluded from product compliance status evaluation.
CUST_NOTE2	50 Image
China ROHS	Not Relevant
ELV	Not Contained*
RoHS Phthalates	

Search Parts in this Series
[120070](#) Series