

TECHNICAL SPECIFICATIONS
D-Sub Hood:

Material: Zinc, Nickel Plated
 Operating Temperature: -45°C to + 105°C
 Cable Entry: Top Entry
 Thumbscrews: UNC 4-40 (Standard)

Cable O.D - Standard:


9-Way: Up to 6,5mm with grommet - 9,5mm without grommet
 15-Way: Up to 6,5mm with grommet - 12,5mm without grommet
 25-Way: Up to 8.0mm with grommet - 12,5mm without grommet
 37-Way: Up to 9.0mm with grommet - 15,0mm without grommet

High Density D-Sub Solder Cup:

Insulator: Glass filled TP, UL94 V-0
 Shell: Steel, Tin Plated
 Contact pins: Copper Alloy
 Stamped & Formed Pins: Class 3, 100 inserts min.
 Contact Plating: Gold flash over Nickel
 Operating Temperature: -55°C to +85°C
 Withstanding voltage: >1000V Rms to 50 Hz for 1 minute
 Current Rating: 3A
 Insulator resistance: >5000MΩ min.

Features:

- Available in sizes HD15-26-44-62
- Excellent EMI Shielding
- Re-openable
- Spring-Clip mounted Jackscrews

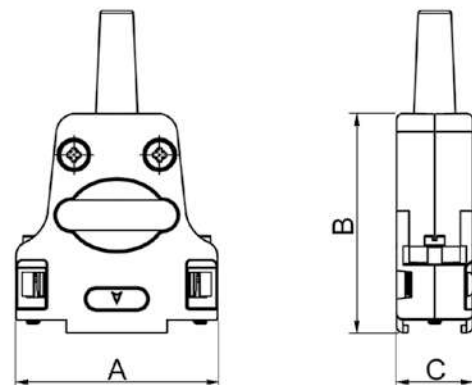

| Size DTZF | Dim A | Dim B | Dim C |
|-----------|-------|-------|-------|
| 9-way | 31,6 | 39,5 | 15,2 |
| 15-way | 40,0 | 41,0 | 15,2 |
| 25-way | 53,7 | 47,5 | 15,2 |
| 37-way | 70,2 | 48,0 | 15,2 |

Ordering information:
High Density D-Sub Connector Kits

| Size: | P/N - Kitted: | Description: |
|-------|-------------------------|---------------------|
| HD 15 | L17DTZF09-RG+L717HDE15P | Solder Cup, 15-Male |
| HD 26 | L17DTZF15-RG+L717HDA26P | Solder Cup, 26-Male |
| HD 44 | L17DTZF25-RG+L717HDB44P | Solder Cup, 44-Male |
| HD 62 | L17DTZF37-RG+L717HDC62P | Solder Cup, 62-Male |

| Size: | P/N - Kitted: | Description: |
|-------|------------------------|-----------------------|
| HD 15 | L17DTZF09-RG+L77HDE15S | Solder Cup, 15-Female |
| HD 26 | L17DTZF15-RG+L77HDA26S | Solder Cup, 26-Female |
| HD 44 | L17DTZF25-RG+L77HDB44S | Solder Cup, 44-Female |
| HD 62 | L17DTZF37-RG+L77HDC62S | Solder Cup, 62-Female |