

## Plastic Hoods

## D45PK-P+Screw Type Connector

### TECHNICAL SPECIFICATIONS

#### D-Sub Hood:

Material:	UL 94 V-0 Plastic Material
Operating Temperature:	-55°C to +110°C
Cable Entry:	Side
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D:	Up to 11,5mm
Colour:	Black





#### D-Sub Screw Connector:

Insulator:	Glass filled TP, UL94 V-0
Shell:	Steel, Tin Plated
Contact pins:	Machined Brass pins 15µ" Gold plated over Ni.
AWG Wire Size:	AWG 18
Contact Plating:	Gold flash over Nickel
Operating Temperature:	-55°C to +85°C
Withstanding voltage:	>1000V Rms to 50 Hz for 1 minute
Current Rating:	7.5A
Insulator resistance:	>5000MΩ min.




#### Features:

- Available in sizes 9-15-25
- Strain relief inserts ensure a secure termination
- Re-openable

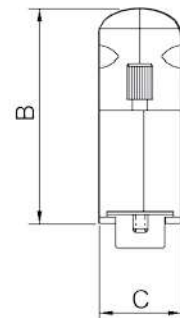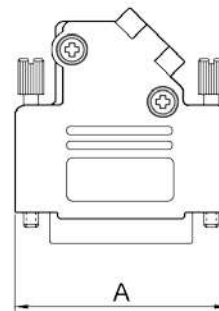

#### Grommet Sizes D45PK-P:

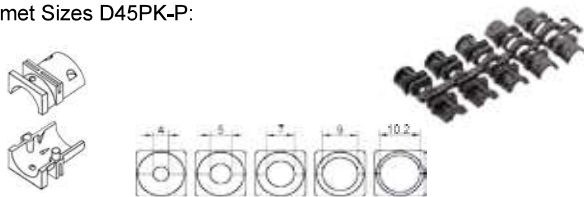

Size D45PK-P	Dim A	Dim B	Dim C
9-way	31,0	36,3	15,0
15-way	39,5	40,3	15,0
25-way	53,2	40,3	15,0

### Ordering information:

### Screw Connector D-Sub Connector Kits

Size:	P/N - Kitted:	Description:
9-way	L17D45PK-P-09+L717DE09PST	Screw type, 9-Male
15-way	L17D45PK-P-15+L717DA15PST	Screw type, 15-Male
25-way	L17D45PK-P-25+L717DB25PST	Screw type, 25-Male

Size:	P/N - Kitted:	Description:
9-way	L17D45PK-P-09+L77DE09SST	Screw type, 9-Female
15-way	L17D45PK-P-15+L77DA15SST	Screw type, 15-Female
25-way	L17D45PK-P-25+L77DB25SST	Screw type, 25-Female