

11 05 160


Insulation Stripper



- For single, multiple and fine stranded conductors with plastic or rubber insulation up to 5.0 mm dia. or 10 mm² cable cross-section
- Easy adjustment to the required diameter of solid or stranded wire with knurled screw and lock nut
- Special tool steel, forged, oil-hardened



Article No.	11 05 160
EAN	4003773039570
Pliers	chrome plated
Handles	with multi-component grips
Style	0
Head	
Stripping capacities in square millimetres mm²	10,0
Nominal size	160 mm
Stripping capacities (diameter) Ø mm	5,0
AWG	7
Length mm	160
Net weight g	157

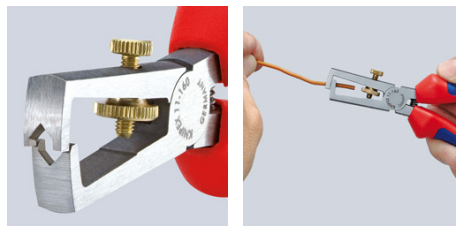

technical change and errors excepted



Spare Parts

Article No.	EAN	
11 09 01	4003773052326	Set of spare parts (screw and nut) for 11 160