

# 11 06 160


## Insulation Stripper



- For single, multiple and fine stranded conductors with plastic or rubber insulation up to 5.0 mm dia. or 10 mm<sup>2</sup> cable cross-section
- Easy adjustment to the required diameter of solid or stranded wire with knurled screw and lock nut
- Special tool steel, forged, oil-hardened



<b>Article No.</b>	11 06 160
<b>EAN</b>	4003773021933
<b>Pliers</b>	chrome plated
<b>Handles</b>	insulated with multi-component grips, VDE-tested
<b>Style</b>	0
<b>Head</b>	
<b>Insulation standard</b>	IEC 60900 DIN EN 60900
<b>Stripping capacities in square millimetres mm<sup>2</sup></b>	10,0
<b>Nominal size</b>	160 mm
<b>Stripping capacities (diameter) Ø mm</b>	5,0
<b>AWG</b>	7
<b>Length mm</b>	160
<b>Net weight g</b>	166

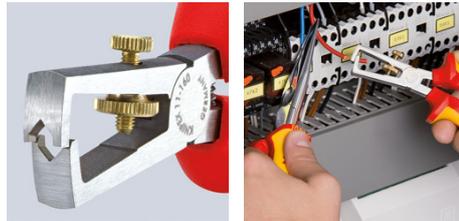

technical change and errors excepted



### Spare Parts

<b>Article No.</b>	<b>EAN</b>	
11 09 01	4003773052326	Set of spare parts (screw and nut) for 11 160