


12 40 200

Self-Adjusting Insulation Stripper



- For single, multiple and fine stranded conductors with plastic or rubber insulation
- Adapts automatically to the respective cable cross-section; prevents damage to the conductor
- Cutting depth can be adjusted for different insulation materials
- With wire cutter for copper and aluminium wires, multiple stranded up to 10 mm² and single stranded up to 6 mm²
- Smoothly operating mechanism
- Stripping blades and clamping jaws easily replaceable
- Low weight
- Body: plastic, fibreglass-reinforced
- Blade: special tool steel, oil-hardened
- For thin ribbon cables up to 10.0 mm width in a single pass

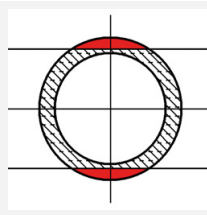


Mode of operation of straight cutters

An incision is made in the red area only.

Not suitable for highly-flexible or armoured insulation materials or for multi-layered insulation.


Article No.	12 40 200
EAN	4003773026662
Stripping capacities in square millimetres mm²	0,03 - 10,0
Length stop mm	3,0 - 18,0
Nominal size	200 mm
AWG	32 - 7
Length mm	200
Net weight g	202

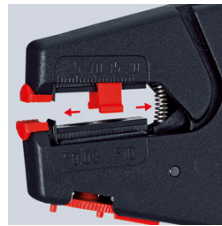

12 40 200: Adjustable length stop



Wire cutter for multiple stranded wire cables up to 10.0 mm²

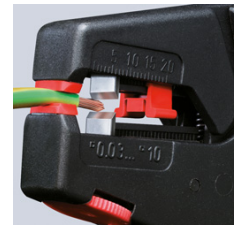

12 40 200: Precise stripping prevents damage to the conductor

technical change and errors excepted



Spare Parts

Article No.	EAN	
12 49 01	4003773026679	1 pair of spare blades for 12 40 200
12 49 02	4003773026686	1 pair of spare clamping jaws for 12 40 200
12 49 03	4003773026693	Spare length stop for 12 40 200
12 49 04	4003773053071	Torsion spring for 12 40/50 200
12 49 05	4003773053088	Coil spring in the head for 12 40/50 200