

# 12 80 040 SB


## Mini Stripping Tool



- Precise stripping, stepwise adjustment to the conductor diameters
- With wire cutter
- Adjustable length stop from 4.0 - 15.0 mm
- With locking device
- Housing: plastic, impact-proof
- For thin copper conductors dia. 0.12 to 0.4 mm



|   |               |
|---|---------------|
| <b>Article No.</b>                          | 12 80 040 SB  |
| <b>EAN</b>                                  | 4003773071655 |
| <b>Stripping capacities (diameter) Ø mm</b> | 0,12 - 0,4    |
| <b>AWG</b>                                  | 36 - 26       |
| <b>Length mm</b>                            | 100           |
| <b>Net weight g</b>                         | 35            |

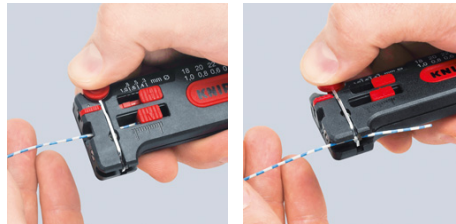

*technical change and errors excepted*

