

# 61 01 200

## Bolt End Cutting Nipper high lever transmission




- Powerful, compact, comfortable
- Compared to conventional lever-assisted end cutting nippers, greater cutting capacity, less effort required and better handling
- For all wire classes including piano wire
- Exceptional cutting capacity due to high-leverage joint
- Cutting edges additionally induction hardened, cutting edge hardness approx. 64 HRC
- Vanadium electric steel, forged, multi stage oil-hardened


Article No.	61 01 200
EAN	4003773033172
Pliers	black atramentized
Head	polished
Handles	plastic coated
Cutting capacities medium hard wire (diameter) Ø mm	4,0
Cutting capacities hard wire (diameter) Ø mm	3,5
Cutting capacities piano wire (diameter) Ø mm	3,0
Cutting capacities soft wire (diameter) Ø mm	1,0 - 6,0
Length mm	200
Net weight g	435



Extraordinary cutting performance: also for piano wire

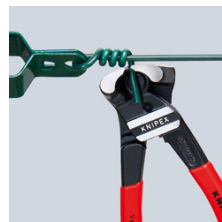

Particularly efficient for fence construction

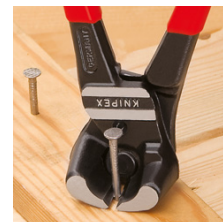

Almost flush cutting of bolts, nails etc.

technical change and errors excepted

