

75 52 125


Electronics Diagonal Cutter



- Bolted joint for high precision and stress tolerance
- For ultra fine cutting work, e.g. in electronics and fine mechanics
- With sharp, ground cutting edges for soft and hard wire and piano wire
- Cutting edges additionally induction hardened, cutting edge hardness approx. 64 HRC
- Low-friction double spring for gentle and even opening
- High-grade special tool steel, forged, multi stage oil-hardened
 - Style: particularly narrow head, with bevel



Article No.	75 52 125
EAN	4003773040576
Pliers	burnished
Handles	with plastic grips
Style	5
Cutting capacities medium hard wire (diameter) Ø mm	0,5
Cutting capacities hard wire (diameter) Ø mm	0,3
Cutting capacities soft wire (diameter) Ø mm	0,2 - 0,8
B mm	14
D mm	6,5
A mm	10,5
Length mm	125
Net weight g	79

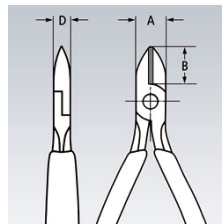

Bolted joint

technical change and errors excepted

