


78 61 125

Electronic *Super Knips*®



- Precision pliers for ultra fine cutting work, e. g. in electronics and fine mechanics
- Ground, very sharp cutting edges without bevel
- Shear cut with controlled micro cutting edge misalignment for the most precise cutting of even the thinnest of wires and for a long service life
- Precision shaped tips cut wires resting on a board from 0.2 mm dia.
- Joint with stainless steel rivet
- Extremely smooth movement for minimum operator fatigue
- With opening spring and opening limiter
- Also suitable for cutting glass fibre cables (fibre optics)
- Cutting edges additionally induction hardened, cutting edge hardness approx. 64 HRC
- Special tool steel, oil hardened in multiple stages

| | |
|--|----------------------------|
| Article No. | 78 61 125 |
| EAN | 4003773035404 |
| Pliers | burnished |
| Handles | with multi-component grips |
| Style | 6 |
| Head | |
| Cutting capacities medium hard wire (diameter) Ø mm | 1,2 |
| Cutting capacities soft wire (diameter) Ø mm | 0,2 - 1,6 |
| D mm | 7,5 |
| B mm | 9,0 |
| A mm | 13,5 |
| Length mm | 125 |
| Net weight g | 56 |

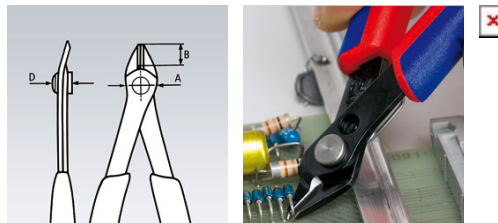

technical change and errors excepted

