

87 02 180 T

KNIPEX Cobra® with tether attachment point with tether attachment point



- Push the button for adjustment on the workpiece
- Fine adjustment for optimum adaptation to different sizes of workpieces and a comfortable handle width
- Self-locking on pipes and nuts: no slipping on the workpiece and low handforce required
- Gripping surfaces with special hardened teeth, teeth hardness approx. 61 HRC: high wear resistance and stable gripping
- Box-joint design for high stability due to double guide
- Reliable catching of the hinge bolt: no unintentional shifting
- Guard prevents operators' fingers being pinched
- Chrome vanadium electric steel, forged, multi stage oil-hardened
- Pliers with tether attachment point for mounting a fall protection

KNIPEX Cobra® - the Hightech Water Pump Pliers. No more time-consuming presetting of the required opening size. Just position the upper jaw to the workpiece, push button and move close the lower jaw, ingeniously simple.


| | |
|---|---|
| Article No. | 87 02 180 T |
| EAN | 4003773080145 |
| Pliers | grey atramentized |
| Head | polished |
| Handles | with multi-component grips, with integrated tether attachment point for a tool tether |
| Adjustment positions | 18 |
| Capacity for pipes, inches (diameter) Ø Inch | 1 1/2 |
| Capacities for nuts mm | 36 |
| Capacities for pipes (diameter) Ø mm | 42 |
| Length mm | 180 |
| Net weight g | 200 |




Fine adjustment by pushing a button: fast and comfortable.



Fast and firm adjustment directly on the workpiece

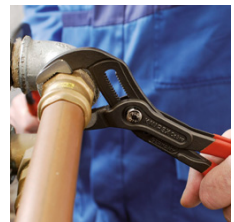

Teeth set against the direction of rotation have a self-locking effect and prevent slipping on the workpiece.

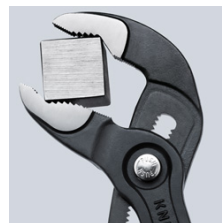

technical change and errors excepted



