

# 88 01 300

## KNIPEX Alligator® Water Pump Pliers




- More output and comfort compared to conventional water pump pliers of the same length: 9-notch adjustment positioning for 30 % more gripping capacity
- Good access to the workpiece due to slim size of head and joint area
- Self-locking on pipes and nuts: no slipping on the workpiece and low handforce required
- Gripping surfaces with special hardened teeth, teeth hardness approx. 61 HRC: high wear resistance and stable gripping
- Box-joint design for high stability due to double guide
- Robust construction, insensitive to dirt; particularly suitable for outdoor work
- Guard prevents operators' fingers being pinched
- Chrome vanadium electric steel, forged, multi stage oil-hardened



|  |                               |
|--|-------------------------------|
| Article No.                                  | 88 01 300                     |
| EAN  | 4003773034094                 |
| Pliers                                       | black atramentized            |
| Head   | polished                      |
| Handles                                      | with non-slip plastic coating |
| Adjustment positions                         | 9                             |
| Nominal size                                 | 300 mm                        |
| Capacity for pipes, inches (diameter) Ø Inch | 2 3/4                         |
| Capacities for nuts mm                       | 60                            |
| Capacities for pipes (diameter) Ø mm         | 70                            |
| Length mm                                    | 300                           |
| Net weight g                                 | 511                           |



Self-locking on pipes and nuts: no slipping on the workpiece; the complete actuating force can be used to turn the workpieces; not having to squeeze the pliers handles reduces the required effort

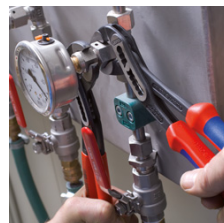

technical change and errors excepted

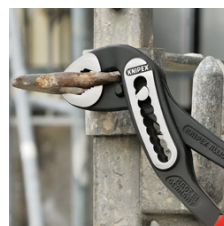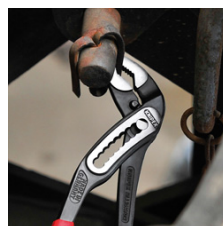

### Spare Parts

| Article No. | EAN           |                          |
|-------------|---------------|--------------------------|
| 88 09 300   | 4003773053521 | Bolt (Kerpin) for 88 300 |