

88 02 250 T

KNIPEX Alligator® with tether attachment point with tether attachment point




- More output and comfort compared to conventional water pump pliers of the same length: 9-notch adjustment positioning for 30 % more gripping capacity
- Good access to the workpiece due to slim size of head and joint area
- Self-locking on pipes and nuts: no slipping on the workpiece and low handforce required
- Gripping surfaces with special hardened teeth, teeth hardness approx. 61 HRC: high wear resistance and stable gripping
- Box-joint design for high stability due to double guide
- Robust construction, insensitive to dirt; particularly suitable for outdoor work
- Guard prevents operators' fingers being pinched
- Chrome vanadium electric steel, forged, multi stage oil-hardened
- Pliers with tether attachment point for mounting a fall protection
- With slim multi-component grips without collar for better handling and easier transport

Article No.	88 02 250 T
EAN	4003773080176
Pliers	black atramentized
Head	polished
Handles	with slim multi-component grips, with integrated tether attachment point for a tool tether
Adjustment positions	9
Capacity for pipes, inches (diameter) Ø Inch	2
Capacities for nuts mm	46
Capacities for pipes (diameter) Ø mm	50
Length mm	250
Net weight g	370



Self-locking on pipes and nuts: no slipping on the workpiece; the complete actuating force can be used to turn the workpieces; not having to squeeze the pliers handles reduces the required effort

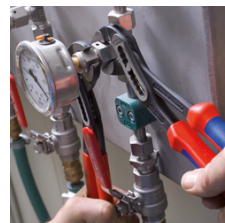

technical change and errors excepted

