

# 94 55 200

## Anvil shears




- Drawing cut against firm surface for cutting soft materials without damage, e.g. rubber profiles, PVC, leather, wood, hoses etc.
- Cuts flat material with a max. width of 40 mm and height of 7.5 mm
- Cutting capacity for round material up to  $\varnothing$  25 mm
- Strong, replaceable blade
- With opening spring and locking device
- Tool body: tool steel, rolled, oil-hardened



<b>Article No.</b>	94 55 200
<b>EAN</b>	4003773080763
<b>Tool</b>	chrome plated
<b>Handles</b>	with plastic grips
<b>Blade length mm</b>	40
<b>Length mm</b>	200
<b>Net weight g</b>	290



*technical change and errors excepted*

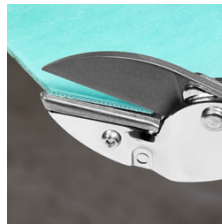

### Spare Parts

Article No.	EAN	
94 59 200 01	4003773080916	Spare blade for 94 55 200
94 59 200 02	4003773080923	Spare anvil for 94 55 200