


97 49 05

Crimping dies for non-insulated open plug-type connectors 4.8 + 6.3 mm

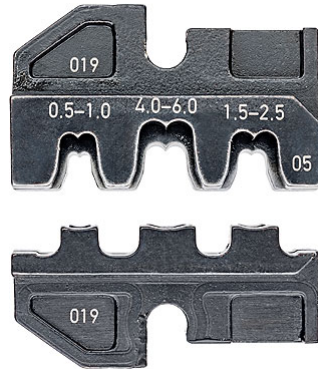

Article No.	97 49 05
EAN	4003773030867
Applications	non-insulated open plug type connectors (plug width 4.8 + 6.3 mm)
Capacity in square millimetres mm²	0,5 - 6,0
Number of crimping positions	3
AWG	20 - 10
Net weight g	46

technical change and errors excepted



Accessories

Article No.	EAN	
97 49 95	4003773031000	Locator for 97 49 05

Products

No.	EAN	
97 43 200	4003773030812	Crimp System Pliers for exchangeable crimping dies
97 43 E	4003773076858	
97 43 E AUS	4003773076872	
97 43 E UK	4003773076865	
97 43 E US	4003773077008	