

97 53 08

Self-Adjusting Crimping Pliers for End Sleeves (ferrules) with front loading




PATENTED



- For crimping end sleeves (ferrules) according to DIN 46228 parts 1 + 4
- Self-adjusting adaptation to the desired end sleeve (ferrule) size: no wrong crimps caused by using the wrong die
- Front loading of the end sleeves (ferrules) into the tool
- Repetitive, high crimping quality due to integral lock (self-releasing mechanism)
- Crimping pressure has been set precisely (calibrated) in the factory, re-adjustable
- Optimum transmission of force thanks to toggle lever for fatigue-reduced operation
- Handy shape and low weight provide high operation comfort
- Chrome vanadium electric steel in special quality, oil-hardened
- Compression from 0.08 - 10.0 mm² in one profile
- End sleeves (ferrules) up to 2.5 mm² can also be loaded parallelly from the side
- Suitable in particular for all twin end sleeves (ferrules) up to 2 x 4 mm² or 2 x AWG 10

The crimping pliers for end sleeves (ferrules) with three great advantages for the user: - Automatic self-adjustment to the end sleeve (ferrule) used: this allows the specialist to work with less strain and enables secure, reliable and quick crimping. - Range of applications also for large cross-sections: square crimping 0.08 to 10.0 + 16.0 mm² - Front loading: very helpful under difficult working conditions in confined areas.


| | |
|--|----------------------------|
| Article No. | 97 53 08 |
| EAN | 4003773040187 |
| Pliers | burnished |
| Handles | with multi-component grips |
| Applications | End Sleeves (ferrules) |
| Capacity in square millimetres mm² | 0,08 - 10 |
| Number of crimping positions | 1 |
| AWG | 28 - 7 |
| Length mm | 190 |
| Net weight g | 477 |

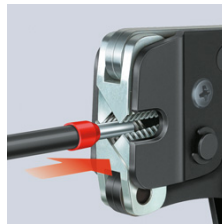

Front loading of end sleeves (ferrules) e.g. in switchboards



Square compression

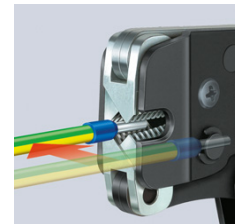

97 53 08: lateral loading of end sleeves (ferrules) up to 2.5 mm² parallelly from the side e.g. in confined areas

technical change and errors excepted



Spare Parts

| | | |
|--------------------|---------------|---------------------------------------|
| Article No. | EAN | |
| 97 59 30 | 4003773053965 | Extension spring for 97 53 4/5/8/9/14 |

| | | |
|----------|---------------|---------------------------------------|
| 97 59 31 | 4003773053972 | Extension spring for 97 53 4/5/8/9/14 |
| 97 59 32 | 4003773053989 | Circlips for model 97 53 for 97 53 xx |