




Floor Lamp, LED, Slim Head, Touch Sensitive 22-26075

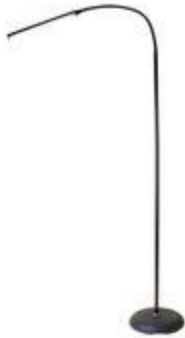

Specifications

Brightness	350 Lumens
Number of LEDs	28
LED Life	30,000 Hours (approximate)
Power Consumption: 5.5W	
Power Supply	12V 0.42A DC Adapter (included)
Power Source	110~240V AC 50/60 Hz
Dimensions	Total height 66", 15" of total height is Flexible Gooseneck

This bright, white LED lamp that is perfect for your technician bench, but presentable enough for use in living spaces. The flexible, obedient neck lets you aim the bright, white LEDs where you need light. The touch-sensitive power switch features four brightness modes.

- Slim-head design allows heads to be adjusted in multiple angles, narrow or wide
- Compact size fits in any work space
- Flexible arm positions light to any angle
- Touch-sensitive power and level control
- 4 levels of dimming for adjustable brightness
- Built-in LED Lights are bright and energy efficient
- LEDs are diffused for an even, low-glare light
- Bright, day-light white LEDs
- Ideal for technician benches, desks, or pianos
- Floor stand