


**Part Number:** [0002061101](#)  
**Status:** Active  
**Overview:** Standard .062" Pin and Socket Power Connectors  
**Description:** 1.57mm Diameter, Standard .062" Pin and Socket Crimp Terminal, Female, with Tin (Sn) Plated Brass Contact, 18-24 AWG, Reel

**Documents:**

[図面 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[製品仕様書 PS-02-06-001 \(PDF\)](#)

一般用途	Power, 電線対電線
Crimp Quality Equipment	有
概要	<u>Standard .062" Pin and Socket Power Connectors</u>
梱包違い製品	<u>02-06-1103 (Loose)</u>
製品名	Standard .062"
UPC	800753615984
機械的性能/材質	
ジェンダー	フィメール
材質 - 金属部	黄銅
材質 - 嵌合部メッキ	錫
材質 - ターミナルメッキ	錫
Net Weight	0.147/g
梱包形態	リール
嵌合部メッキ厚	0.508µm
ターミナルメッキ厚	0.508µm
実装スタイル	圧着またはコンプレッション
被覆外径	1.52-3.05mm
電線サイズ (AWG)	18, 20, 22, 24
Wire Size mm <sup>2</sup>	N/A
Solder Process Data	
Lead-freeProcess Capability	N/A
参考情報	
Engineering Number	1561-(P901)
図面・仕様書情報	
製品仕様書	PS-02-06-001
製品図面	SD-1561-*

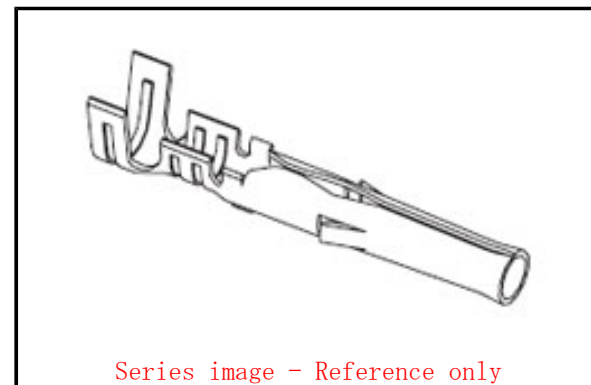

Series image - Reference only

EU ELV  
Not Relevant

EU RoHS China RoHS  
Compliant

REACH SVHC  
Not Contained Per -  
ED/61/2018 (27 June  
2018)

Halogen-Free  
Status

Low-Halogen

For more information, please visit  
Contact US

China ROHS Green Image  
ELV Not Relevant  
RoHS Phthalates Not Contained

Search Parts in this Series  
[1561](#) Series