


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0430250600](#)
Status: **Active**
Overview: [Micro-Fit 3.0 Connector System Product Family](#)
Description: [Micro-Fit 3.0 Receptacle Housing, Dual Row, 6 Circuits, UL 94V-0, Low-Halogen, Black](#)

Documents:

| | |
|--|--|
| Drawing (PDF) | Product Specification TS-46235-001-001 (PDF) |
| 3D Model | Application Specification 430250000-AS-000 (PDF) |
| Product Specification PS-43045 (PDF) | Packaging Specification PK-43025-001-001 (PDF) |
| Product Specification PS-43045-001 (PDF) | RoHS Certificate of Compliance (PDF) |
| Product Specification TS-43045-001-001 (PDF) | Product Literature (PDF) |

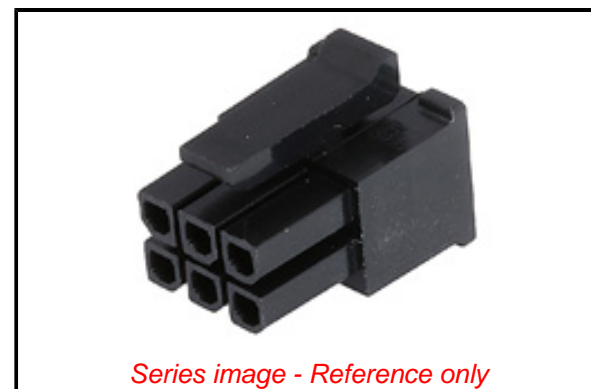

Series image - Reference only

Agency Certification

| | |
|-----|---------|
| CSA | LR19980 |
| UL | E29179 |

General

| | |
|-----------------------------|---|
| Product Family | Crimp Housings |
| Series | 43025 |
| Application | Power, Wire-to-Board, Wire-to-Wire |
| Overview | Micro-Fit 3.0 Connector System Product Family |
| Product Literature Order No | 987650-5984 |
| Product Name | Micro-Fit 3.0 |
| UPC | 800753683617 |

Physical

| | |
|-------------------------------|----------------|
| Circuits (maximum) | 6 |
| Color - Resin | Black |
| Flammability | 94V-0 |
| Gender | Receptacle |
| Glow-Wire Capable | No |
| Keying to Mating Part | None |
| Lock to Mating Part | Yes |
| Material - Resin | Nylon |
| Net Weight | 0.570/g |
| Number of Rows | 2 |
| Packaging Type | Bag |
| Panel Mount | No |
| Pitch - Mating Interface | 3.00mm |
| Polarized to Mating Part | Yes |
| Stackable | No |
| Temperature Range - Operating | -40° to +105°C |

Solder Process Data

| | |
|-----------------------------|-----|
| Lead-freeProcess Capability | N/A |
|-----------------------------|-----|

Material Info

Reference - Drawing Numbers

| | |
|---------------------------|--|
| Application Specification | 430250000-AS-000 |
| Packaging Specification | PK-43025-001-001 |
| Product Specification | PS-43045, PS-43045-001, TS-43045-001-001, TS-46235-001-001 |
| Sales Drawing | 430250000-SD-000 |

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[43025](#) Series

Mates With

Micro-Fit 3.0 Plug Housings [43020](#) , Micro-Fit 3.0 Headers [43045](#) , Micro-Fit 3.0 Test Plug [44242](#)

Use With

Micro-Fit 3.0 Female Crimp Terminals [43030](#) , [45773](#) , Micro-Fit RMF Female Crimp Terminals [46235](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION